

Control multiple servers around your building from one location




Manage all of your computers from one convenient location with a StarView CAT5 KVM switch. StarView CAT5 KVM switches let you connect multiple computers using only one keyboard, mouse, and monitor over CAT5 cabling. Using CAT5 cable to link the computers improves cabling efficiency and extends the reach beyond standard KVM cables (up to 130 feet per cable to multiple locations).

The convenient pushbutton and hot-key commands allow for quick, reliable switching between your systems. Manual and Auto scan modes are supported. Our slim design needs only 1U in your cabinet and uses rear cable connections for maximum space efficiency. Available in 8 and 16 port models, they can be cascaded to support up to 512 computers providing additional flexibility as your organization grows.



8 Port: SV831DUTP
 16 Port: SV1631DUTP

Cat5 KVM Solution

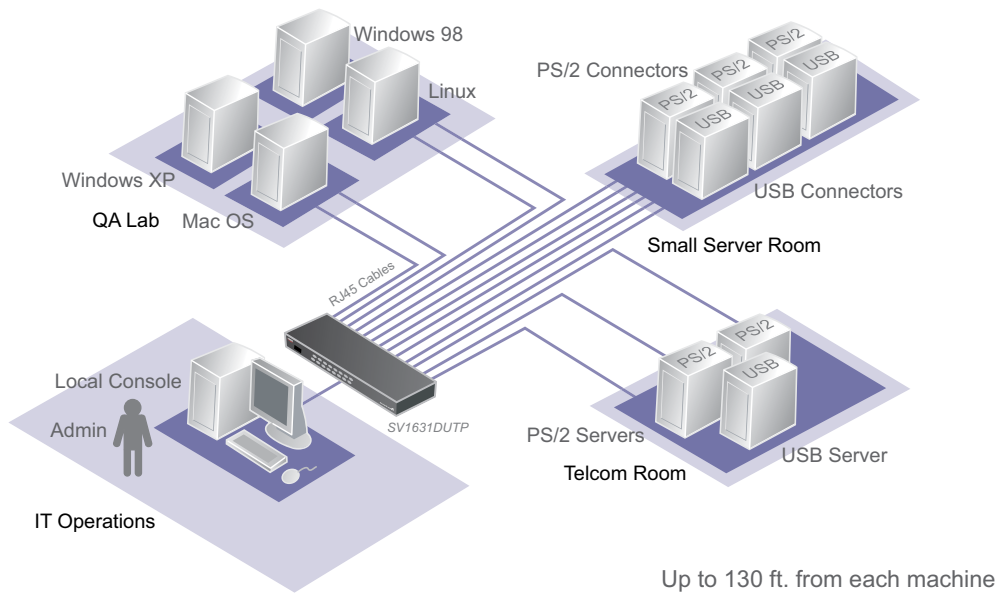

Benefits:

- Cat5 cables support distances of up to 130 ft.
 - much longer than USB cables
- Cables can be color coded - to improve organization
- Allows cables already installed in network infrastructure to be used - saving time and money
- Auto-scan function automatically selects computer sequentially
- Cascade configuration expands system capability up to 512 computers
- Easy to use computer selection via port selection switches, Hotkeys and intuitive On Screen Display (OSD) menus
- Hot Pluggable - add or remove computers without having to power down the switch
- Multiplatform support: Windows, Mac, Sun and terminal-based systems
- Free life-time technical support

Applications

- Enterprise network management
- Manufacturing line computer control
- PC test/burn-in computer control
- Server farms



16 Port: SV1631DUTP

The StarTech.com
Advantage:

- Long distance CAT5 connectivity for your servers
- Exceptional video quality, supporting up to 1600 x 1200 @ 60Hz
- Two level password security prevents unauthorized access
- Versatile - connect to PS2 or USB servers with dongles (SV5USBS and SV5PS2S)

Comparison Matrix

Features	StarTech.com	Belkin	Minicom	Aten
Model	SV831DUTP	F1DP108A	0SU22002	KH1508
MSRP (USD)	\$359.99	\$399.99	\$395.00	\$399.99
# of ports:	8	8	8	8
RJ-45	✓	✓	✓	✓
Distance	130'	100'	100'	130'
Max. Resolution	1600 x 1200	1600 x 1200	1600 x 1200	1600 x 1200
Auto-Scan PC Selection	✓	✓	-	✓
OSD (on screen display)	✓	✓	✓	✓
Hot Pluggable to PCs	✓	-	-	✓
Cascade support (# of units)	506	256	256	256
Connected to USB PCs	✓	✓	✓	✓
Connected to PS/2 PCs	✓	✓	✓	✓
OS Support: Windows, Sun, Mac, Lunix	✓	✓	✓	✓
Programmable Hotkeys	✓	✓	✓	✓
Security	2 Level	1 Level	2 Level	2 Level
Operating Temperature	32-122°F	32-104°F	32-104°F	32-122°F
Lifetime Technical Support	Yes	Yes	No	No

* Limited time pricing