


25m Multimode 50/125 Duplex Fiber Patch Cable LC - LC

StarTech ID: 50FIBLCLC25

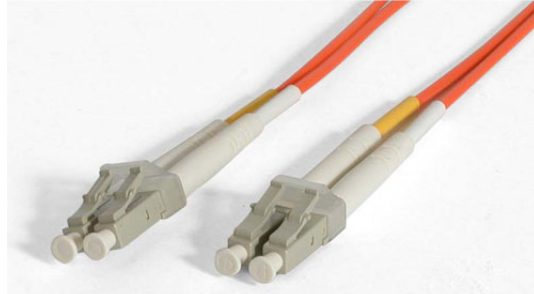

Your company's backbone is its Network. Without a stable, reliable network your company can't communicate. A lack of communication means a loss of revenue. What do you do now? Enter StarTech.com duplex 50/125 Multimode Fiber Optic cables. This product provides the necessary link between Fiber networking devices for high-speed, long-distance networks. Ideal for Gigabit networks, 50/125-micron cables offer nearly three times the bandwidth of 62.5/125-micron cables, so your data will be transferred at higher rates over longer distances.

Applications and Solutions

- Broadband systems
- Ideal solution for data applications requiring high speed data transmission
- Telecommunication / Data communication
- Used by long distance networks with mission critical data

Features

- Connectors offer greater durability in resisting pulls, strains, and impacts during cable installation and maintenance
- Immune to electricity interference

Technical Specifications

- Warranty: Lifetime warranty
- Connector A: 2 - Fiber Optic LC Male
- Connector B: 2 - Fiber Optic LC Male
- Color: Orange
- Fiber Size: 50/125
- Fiber Type: Multi Mode
- Product Length: 82 ft [25 m]
- Carton Quantity: 20
- Shipping (Package) Weight: 0.35 lb [0.16 kg]
- Cable Type: : Duplex Multimode
- Connector A: : LC (male)
- Connector B: LC (male)
- Fiber Size: : 50/125 micron

