


## 40m Multimode 50/125 Duplex Fiber Patch Cable LC - LC (Special Order)

StarTech ID: 50FIBLCLC40

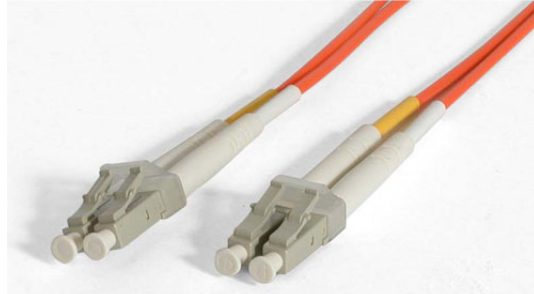

Your company's backbone is its Network. Without a stable, reliable network your company can't communicate. A lack of communication means a loss of revenue. What do you do now? Enter StarTech.com duplex 50/125 Multimode Fiber Optic cables. This product provides the necessary link between Fiber networking devices for high-speed, long-distance networks. Ideal for Gigabit networks, 50/125-micron cables offer nearly three times the bandwidth of 62.5/125-micron cables, so your data will be transferred at higher rates over longer distances.

### Applications and Solutions

- Broadband systems
- Ideal solution for data applications requiring high speed data transmission
- Telecommunication / Data communication
- Used by long distance networks with mission critical data

## Features

- Connectors offer greater durability in resisting pulls, strains, and impacts during cable installation and maintenance
- Immune to electricity interference

## Technical Specifications

- Warranty: Lifetime warranty
- Connector A: 2 - Fiber Optic LC Male
- Connector B: 2 - Fiber Optic LC Male
- Color: Orange
- Fiber Size: 50/125
- Fiber Type: Multi Mode
- Product Length: 131.2 ft [40 m]
- Carton Quantity: 3
- Shipping (Package) Weight: 0.51 lb [0.23 kg]
- Cable Type: : Duplex Multimode
- Connector A: : LC (male)
- Connector B: LC (male)
- Fiber Size: : 50/125 micron

