


2 Port 16550 Serial ISA Card

StarTech ID: ISA2S550

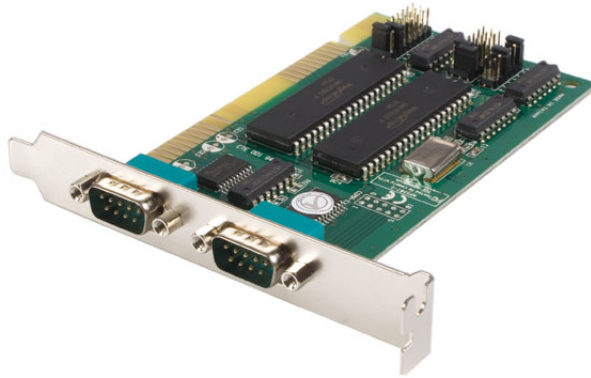

Get more out of your serial devices! StarTech.com's easily configurable ISA2S550 ISA serial expansion card gives you two additional COM ports, with data transfer rates up to 460.8 Kbits/sec.

Perfect for connecting serial modems, POS devices, PDAs, digital cameras, printers, ISDN terminal adapters and more, to your system.

Installation is a breeze with plug and play support and built in drivers for Windows® 3.1, 95, 98, NT4, NT5 Plus, built-in jumpers allow easy configuration to any free IRQ. Backed by StarTech.com's lifetime warranty and FREE LIFETIME tech support.

Applications and Solutions

- **Casino** (video lottery terminals, slot machines)
- **Consumer** (modems, PDAs, digital cameras, printers)
- **Environmental Control** (lighting, temperature, clocks)
- **Healthcare** (patient monitoring equipment, nurses' stations, modems)
- **Hospitality/Restaurant** (credit card/debit card reader, serial printers)
- **Hotel Front Desk** (serial printers, bar code scanners, keyboard, mouse, receipt printer, credit/debit card reader)
- **ISDN Networking**
- **Manufacturing** (CNC machinery, process control equipment, bar code scanners, serial printers)
- **POS** (credit/debit card readers, receipt printers, bar code scanners, cash registers, scales)

- **Security** (UPS control, access key panels, video cameras, card readers, modems)

Features

- Includes drivers for Windows® 3.1, 95, 98, NT4, NT5
- Full jumper set to ensure compatibility with almost any PC system
- Supports the RS-232 interface

Technical Specifications

- Bus Type: ISA
- Chipset ID: MosChip NM9820CV
- Connector Types: 2 - DB9 Male
- Number of Ports: 2
- Carton Quantity: 50
- Shipping (Package) Weight: 0.29 lb [0.13 kg]
- UARTS: 2 x 16C550
- COM Settings: COM1 to COM7
- IRQ Settings: 3,4,5,9,10,11,12,15 for each port
- Clock settings: x1 115.2 Kbits/sec., x2 230.4 Kbits/sec., x4 460.9 Kbits/sec.
- Chipset: NetMos NM9820CV