


1 Port eSATA + 1 Port SATA PCI SATA Controller Card w/ LP Bracket

StarTech ID: PCIESATA2I

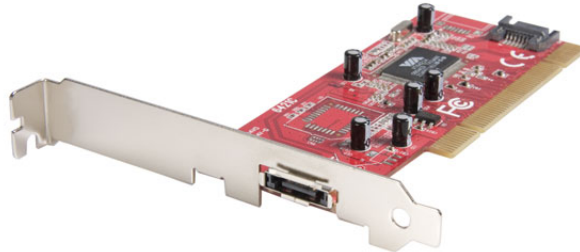

This PCI based SATA Controller Card allows you to turn a PCI slot into one internal SATA and one external SATA (eSATA) connection. Supporting SATA 150 hard drives, and data transfer rates of up to 1.5Gbps, this controller card is the perfect solution if you need an extra SATA port or want to externalize your storage.

Applications and Solutions

- Adds dual SATA channels to upgrade desktops with additional SATA internal drives
- Upgrading PCI bus desktop and server systems to have external eSATA connection to external eSATA devices such as external hard drive storage and optical drives.

Features

- 48 bits LBA can Break Capacity-Limit to Support HDD larger than 137GB
- Compliant with PCI Specification, revision 2.2
- Fully compliant with Serial ATA 1.0a specifications
- Independent 256-byte FIFOs (32 bit x 64 deep) per Serial ATA channel for host reads and writes
- Integrated PCI DMA engines
- Supports Spread Spectrum in receiver

Technical Specifications

- Warranty: 1 Year warranty
- Bus Type: PCI / PCI-X (5 / 3.3V)
- Chipset ID: Via/VT6421
- External Ports: 1 - SATA Data 7-pin Female
- Product Height: 0.79 in [20 mm]
- Internal Ports: 1 - SATA Data 7-pin Female
- Product Length: 4.76 in [121 mm]
- Number of Ports: 2
- Carton Quantity: 50
- Shipping (Package) Weight: 6.35 oz [180 g]
- Product Weight: 1.64 oz [46.6 g]
- Product Width: 2.13 in [54 mm]
- OS Supported: WIN 98SE, 2000, XP 32bit & 64bit, Vista 32bit & 64bit

