


Universal VESA LCD Monitor Mounting Bracket for 19in Rack or Cabinet

StarTech ID: RKLcdbk

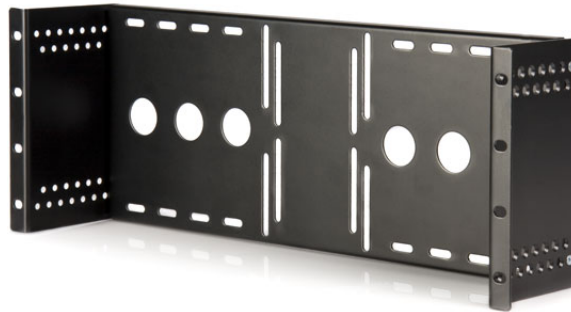

This 19in LCD mounting bracket lets you mount almost any retail LCD or Touch screen panel into a server/storage rack/cabinet. The LCD mounting bracket is designed to support 100mm and 75mm VESA mounted LCD panels, and meets ANSI/EIA RS-310-D standards rack mounting; the bracket features a unique adjustable design that enables an LCD panel to be mounted into the cabinet at various depths - allowing the rack/cabinet door to be closed, ensuring optimal server/equipment storage.

A versatile option, the LCD mounting bracket also supports wall-mounted LCD installation, by inverting the adjustable bracket or by adding this bracket to a wall mount bracket or rack, such as the [6U \(10 inch\) Wallmount Bracket for 19" Rack Equipment](#) (WALLMOUNT6) or [8U Open Frame Wall Mount Equipment Rack](#) (RK812WALLO).

Constructed from solid cold pressed steel (SPCC), the server rack LCD mount is designed for long-lasting dependability and backed by StarTech.com's Lifetime warranty.

Applications and Solutions

- Adding a monitoring display to a security rack or cabinet
- Ideal for installing retail LCD monitor into an existing Rack or Cabinet solution
- Installing a touch screen display into a rack or cabinet
- Mounting a LCD monitor or TV to the wall

Features

- Adjustable 100mm and 75mm VESA mounting hole pattern for greater compatibility and control
- Adjustable depth between 0 to 3.5 inches at an increment of .25 of an inch
- Backed by StarTech.com lifetime warranty
- Constructed from solid steel at 2.0mm thick, this bracket is designed for durability
- Meets ANSI/EIA RS-310-D standards

Technical Specifications

- Warranty: Lifetime warranty
- External Height : 6.97 in [177 mm]
- Carton Quantity: 20
- Shipping (Package) Weight: 2.21 lb [1 kg]
- Color: Black
- Frame Type: : Steel
- External Width : 33.15 in [842 mm]
- External Depth : 4.23 in [107.5 mm]
- Internal Width: 17.48 in [444 mm]
- Maximum Mounting Depth:: 3.5 in [88.9 mm]
- Minimum Mounting Depth:: 0 in [0 mm]
- U Height: 4
- Product Weight: 3.76 lb [1.7 kg]

