


36in SATA to Right Angle SATA Serial ATA Cable

StarTech ID: SATA36RA1

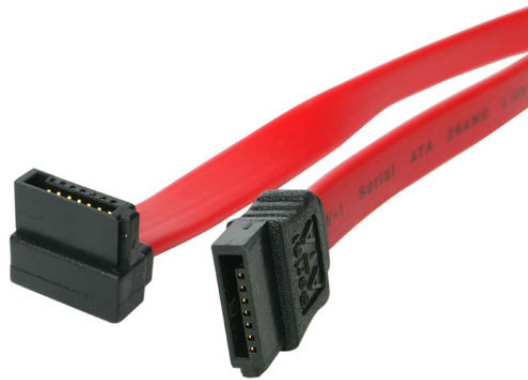

This right angled SATA cable features a standard (straight) male Serial ATA connector as well as a right-angled (male) SATA connector, providing a simple 36in connection to a Serial ATA drive even if space near the drive's SATA port is limited.

Once the right-angled SATA connector has been inserted into the drive's SATA data port, the shaft of the cable is seated flush with the rear panel of the drive, eliminating the clutter of excess cable at the connection point - an ideal solution for small or micro form factor computer cases.

The right angled SATA cable features a thin, narrow construction that helps to improve airflow within the computer case; the cable also features a rugged, yet flexible design that makes it easy to make the SATA connection as needed, and is backed by StarTech.com's Lifetime Warranty.

Applications and Solutions

- ATA Drive Arrays
- Compatible with Serial ATA Hard Drives, CD-RW, DVDs, and other devices
- For use in servers and storage subsystems
- High-end workstations
- Mini tower computers

Features

- Compliant with Serial ATA II Specifications
- Fast data transfer rate of up to 300 Mbytes/Sec
- Meets current Serial ATA II specifications and ensures maximum performance
- Offers 18 inches in length for greater flexibility
- Specially designed to improve system airflow and routability

Technical Specifications

- Warranty: Lifetime warranty
- Connector A: 1 - SATA Data 7 pin Female
- Connector B: 1 - SATA Data 7 pin Female
- Color: Red
- Product Length: 36 in [91.44 cm]
- Maximum Cable Length: 3.28 ft [1 m]
- Carton Quantity: 100
- Shipping (Package) Weight: 0.04 lb [0.02 kg]
- Cable Length: 36 Inches
- Connector Type: 7 pin (female)
- Connector Style:
- Connector A: Straight Connector
- Connector B: Right Angled Connector
- General Specifications: SATA II Compatible

