


36 inch Right Angle Serial ATA Cable (both ends)

StarTech ID: SATARA36

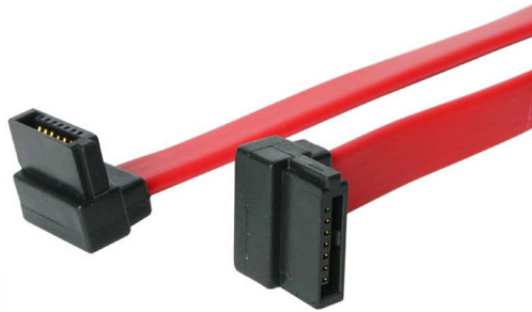

This right angle Serial ATA cable guarantees you'll be able to plug in your high-performance SATA hard drives no matter how tight your space is, using right angled SATA connectors that reduce the amount of space required at the connection point.

Featuring a narrow yet durable construction, and right angled SATA data connectors on both ends of the cable, these flexible cables improve airflow and reduce clutter in your case, helping to keep the case clean and cool.

Constructed of only top quality materials and designed for optimum performance and durability, this right angled SATA cable is backed by our lifetime warranty.

Applications and Solutions

- ATA Drive Arrays
- Compatible with Serial ATA Hard Drives, CD-RW, DVDs, and other devices
- For use in servers and storage subsystems
- High-end workstations
- Mini tower computers

Features

- Compliant with Serial ATA II Specifications
- Fast data transfer rate of up to 300 Mbytes/Sec
- Meets current Serial ATA specifications and ensures maximum performance and reliability
- Offers 36 inches in length for greater flexibility
- Specially designed to improve system airflow and routability

Technical Specifications

- Connector A: 1 - SATA Data 7 pin Female
- Connector B: 1 - SATA Data 7 pin Female
- Color: Red
- Product Length: 36 in [91.44 cm]
- Maximum Cable Length: 3.28 ft [1 m]
- Carton Quantity: 200
- Shipping (Package) Weight: 0.07 lb [0.03 kg]
- Cable Length: 36 Inches
- Connector Type: 7 pin (female)
- Connector Style: Connector A: Straight Connector
 - Connector B: Right Angled Connector
- General Specifications: SATA II Compatible