

4 Port VGA Video Extender over Cat 5 (UTPE Series)

StarTech ID: ST124UTPE




This 4 Port VGA over Cat5 video extender/splitter allows up to 5 (1 local and 4 remote) monitors to be connected to a single VGA source.

The video signal is sent to remote monitors over standard 4 pair Category 5 UTP cable using RJ45 connectors and supports distances of up to 300m / 950ft.

At each remote monitor an STUTPRXL receiver (see accessories) is required to convert the signal from the UTP cable back into VGA video for the monitor.

Applications and Solutions

- Ideal for digital signage applications in financial, educational, and business sectors
- Place the display in a convenient viewing area, while the system equipment is placed elsewhere in a clean and secure environment
- Use digital signage to catch the attention of your audience and deliver up to date content the way you want it to be seen and heard.
- **Digital Signage**

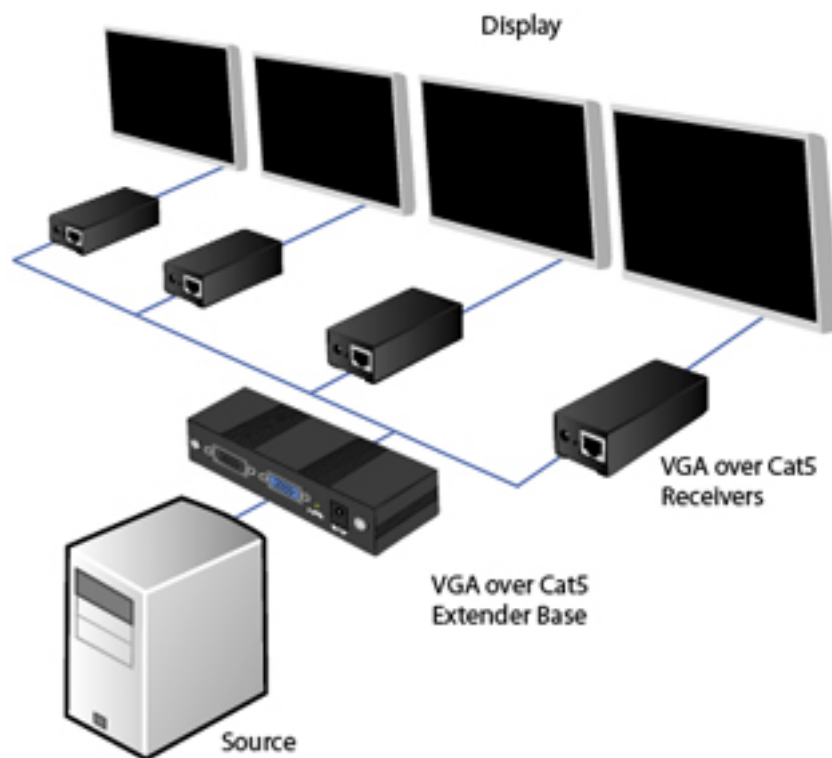

Features

- Cascadable up to three levels
- Monitor receivers are sold separately (See STUTPRXL)
- Monitors can be up to 300m / 950ft away
- Simultaneously displays the same image on 4 monitors
- Supports a maximum resolution of 1024 x 768 @ 60 Hz refresh rate

Technical Specifications

- Color: Black
- Connector Types: 1 - High Density 15 pin Female
- Connector Types: 1 - High Density 15 pin Male
- Connector Types: 4 - RJ45 Female
- Product Height: 1.16 in [29.5 mm]
- Product Length: 3.29 in [83.5 mm]
- Maximum Analog Resolutions: 1280 x 1024
- Number of Ports: 4
- Power Adapter Included: Yes

- Power Adapter - Amperage: 600mA
- Power Adapter - DC Voltage: 12V DC
- Carton Quantity: 10
- Shipping (Package) Weight: 1.97 lb [0.89 kg]
- Product Weight: 8.72 oz [247 g]
- Product Width: 5.12 in [130 mm]