


2 Port DVI Dual Monitor KVM Switch with PS/2

StarTech ID: SV221DVIDD

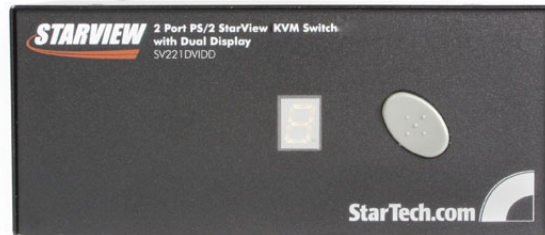

This compact 2-port dual monitor KVM switch (DVI+DVI) offers the ultimate in convenience and cost-savings.

The dual DVI KVM switch lets you instantly switch back and forth between PCs at the touch of a button, while maintaining professional-quality video on both monitors (high digital resolution of up to 1280 x 1024, analog resolutions up to 1920 x 1440).

An ideal solution for graphic designers, CAD/CAM designers or any project requiring dual monitor KVM control, the switch features a compact design, with cable entry positioned at the rear of the switch, saving valuable desk space and eliminating clutter.

A suitable multi-computer control solution for any workspace, the dual DVI KVM switch features a durable metal casing and is backed by our 1-year warranty and free lifetime technical support.

Applications and Solutions

- Designed for Dual DVI monitor enabled PCs
- Ideal for environments using desktops, workstations and servers with Flat Panel LCD monitors

Features

- Draws power from your computer's PS/2 port, does not require a power adapter
- DVI-I interface technology supports both digital and analog video signal transmission
- Front panel LED's indicate which computer is active
- HDCP Compliant
- Keyboard and mouse are hot pluggable, eliminating the need to reboot your systems
- Operating system independent
- Rear connections provide a neat and secure environment
- Supports high digital resolution of up to 1280 x 1024 and analog resolution of up to 1920 x 1440
- Supports PS/2 keyboards and mouse including M/S IntelliMouse, Explorer and Logitech NetMouse
- Switches instantly between two PCs

Technical Specifications

- Warranty: 1 Year warranty
- Color: Black
- Connector Types: 6 - 6 DIN Female
- Connector Types: 4 - DVI-I Dual Link Female
- Enclosure Type: Steel
- Product Height: 2.44 in [6.2 cm]
- Audio Support: No
- KVM Cascadable: No
- Dual Display Support: Yes
- DVI Support: Yes
- Supported Platforms: PS/2
- KVM IP Control: No
- Number of KVM Ports: 2
- Rack-Mountable: No
- KVM TFT: None
- Product Length: 5.51 in [14 cm]
- Maximum Number of Computers: 2
- Maximum Digital Resolutions: 1280 x 1024
- Maximum Analog Resolutions: 1920 x 1440
- Maximum Analog Resolutions: This product is not intended for use with Widescreen displays.
- Maximum Number of Users: 1
- Power Consumption: 0.5
- Carton Quantity: 10
- Shipping (Package) Weight: 1.92 lb [0.87 kg]
- Product Weight: 520
- Product Width: 3.54 in [9 cm]
- PC Connectors: Keyboard: 2 x PS/2 6-pin Mini Din (female)
 - Mouse: 2 x PS/2 6-pin Mini Din (female)
- DVI: 4 x DVI-I Dual Link (female)
- Console Connector: Keyboard: 1 x PS/2 6-pin Mini Din (female)
 - Mouse: 1 x PS/2 6-pin Mini Din (female)
- DVI: 2 x DVI-I Dual Link (female)
- Port Selection: Push Button and Hot Keys

- Power: 9V 500mA Center Positive (optional)
- Operating Temperature: 0C ~ 40C
- LED Indicator: Port Status (Numerical display)
- Dimensions: Length: 5.5 Inches (140 mm)
- Width: 3.4 Inches (86 mm)
- Height: 2.4 Inches (60 mm)
- Weight: 1.1 Lbs (.52 Kgs)
- Enclosure: Metal
- Safety Standards: FCC & CE

