

USB VGA KVM Console Extender w/ Serial & Audio Over Cat5 UTP - 1000 ft

StarTech ID: SV565UTPUSA



This USB VGA serial and audio KVM Console Extender lets you control a server, computer or multiple computers (connected through KVM Switch) over a standard Cat5 or Cat6 UTP network cable connection, at distances of up to 1000ft away over a secure remote connection to a locked (secure) server.

For added convenience, the Console/KVM extender supports USB computer connections, and is compatible with any brand of USB KVM Switch.


The console extender can be mounted to a desk or monitor and features automatic image calibrations for out-of-the-box performance, with manual controls accessible via the serial interface.

[Click here](#) to view the side by side comparison screenshots from the StarTech.com console extender and our leading competitor.

Designed to provide long-lasting, reliable operation, the USB VGA Console Extender is backed by StarTech.com's one year warranty.

Applications and Solutions

• Connectivity Model

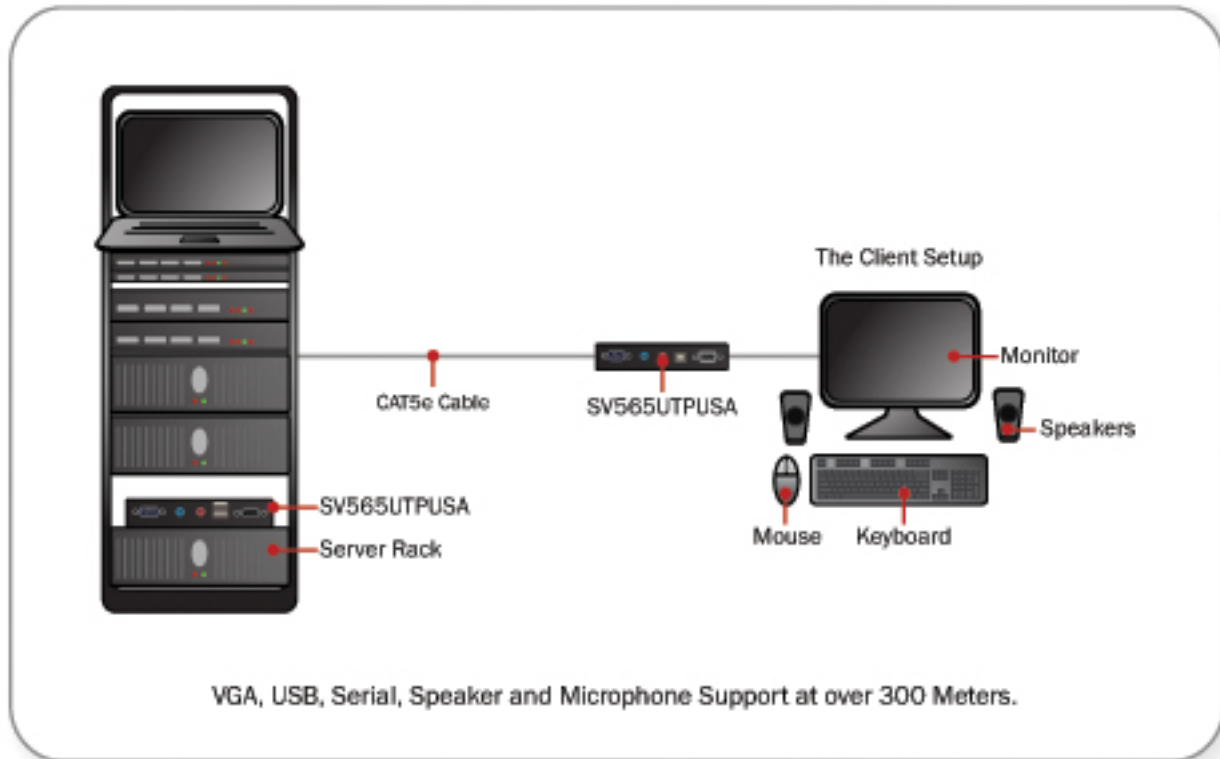

- Extend USB keyboard and mouse, RS232 serial, VGA, and audio up to 1000ft away
- Monitor computer-controlled equipment in a factory or warehouse
- Remotely control secure servers
- Use one or more servers in a server room from a remote location

Features

- Automatic image calibration and adjustment
- High resolution support up to 1920 x 1080 @60Hz
- Manual configuration via serial interface
- Maximum supported distance of 1000ft (300m)
- Mounting brackets on local unit
- Serial devices can be connected at the local station or the remote console
- Transmitter unit is powered by the USB port of the host PC; the remote unit is powered by it's own adapter.
- Upgradable Firmware
- VGA and Audio pass through on remote unit

Technical Specifications

- Color: Black
- Carton Quantity: 14
- Shipping (Package) Weight: 3.12 lb [1.41 kg]
- Enclosure Type: Aluminum
- Audio Support: Yes
- Maximum Analog Resolutions: 1920 x 1080 @60Hz
- Supported Platforms: USB
- KVM Cascadable: Yes
- LED Indicators: 0 - RJ45 Link LED (Local and Remote)
- LED Indicators: 0 - USB Link (Keyboard and Mouse on Local, Single USB on Remote)
- LED Indicators: 0 - Power LED Link (Receiver and Transmitter)
- LED Indicators: 0 - Setup LED (Local)
- Maximum Cable Length: 1000ft (300m)
- Console Interface(s): 1 - High Density DB15 (VGA) Female
- Console Interface(s): 1 - 9 pin D-Sub (DB-9) Male
- Console Interface(s): 2 - USB A Female
- Console Interface(s): 2 - 3.5 mm Stereo Female
- Console Interface(s): 2 - RJ45 Female
- Host Interface(s): 1 - High Density DB15 (VGA) Male
- Host Interface(s): 1 - 9 pin D-Sub (DB-9) Female

- Host Interface(s): 1 - USB B Female
- Host Interface(s): 2 - 3.5 mm Stereo Female
- Host Interface(s): 1 - RJ45 Female
- Other Interfaces: 1 - High Density DB15 (VGA) Female
- Other Interfaces: 1 - 3.5 mm Stereo Female
- Power Adapter Included: Yes
- Input Voltage: 115 ~ 230 AC
- Output Voltage: 5 DC
- Center Tip Polarity: Positive
- Plug Type: N
- Product Width: 6.14 in [156 mm]
- Product Depth: 4.41 in [112 mm]
- Product Height: 1.02 in [26 mm]
- Product Weight: 0.55 lb [0.25 kg]
- Operating Temperature: 0°C to 40°C (32°F to 104°F)
- Storage Temperature: -40°C to 70°C (-40°F to 158°F)
- Humidity: 80% RH