

Reduce Clutter with Cat5 KVM Switches

Manage all your computers from one convenient location with a StarView CAT5 KVM switch. StarView CAT5 KVM switches let you connect multiple computers using only one keyboard, mouse, and monitor over CAT5 cabling. Using CAT5 cable to link the computers reduces cable clutter and extends the reach beyond standard KVM cables (Up to 130 feet).

The convenient pushbutton and hot-key commands allow for quick, reliable switching between your systems. Manual and Auto scan modes are supported. Our slim design needs only 1U in your cabinet and uses rear cable connections for maximum space efficiency. Available in 8 & 16 port models, which can be cascaded to support from 256 to 512 computers providing additional flexibility as your organization grows.

Benefits:

- Reduces cable clutter and supports distances of up to 130 ft.
- Auto-scan function automatically selects computer sequentially
- Cascade configuration expands system capability up to 512 computers
- Easy to use computer selection via port selection switches, Hotkeys and intuitive On Screen Display (OSD) menus
- Hot Pluggable - add or remove computers without having to power down the switch
- Multiplatform support: PC, Mac, Sun and terminal-based systems
- Comes with a 1 year warranty and free life-time technical support

Applications

- Enterprise network management
- Manufacturing line computer control
- PC test/burn-in computer control
- Server farms




8 Port: SV831DUTP
 16 Port: SV1631DUTP

The StarTech.com Advantage:

- Exceptional video quality, supporting up to 1600 x 1200 @ 60Hz
- Two level password security prevents unauthorized access
- Versatile - connect to PS2 and USB devices with Server Interface Modules

Cat5 KVM Solution

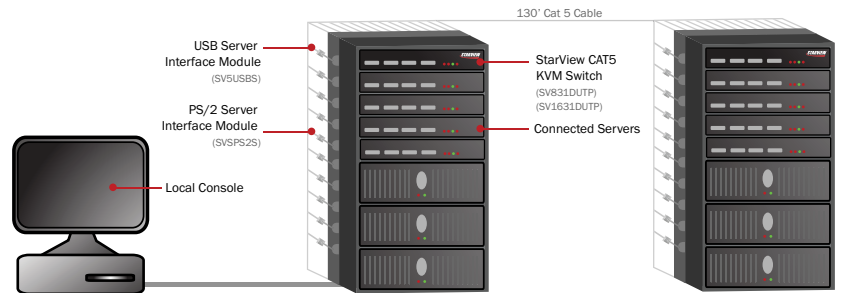

Comparison Matrix

	StarTech.com	Belkin	Avocent	Minicom
Distance	130'	100'	100'	100'
Daisy Chain Ability	512	256	256	256
Hot Pluggable	Yes	No	No	No
Security	2 level	1 level	2 level	2 level