


10 ft IEEE-1394 Firewire 800 Cable 9-4 M/M

StarTech ID: 1394_94_10

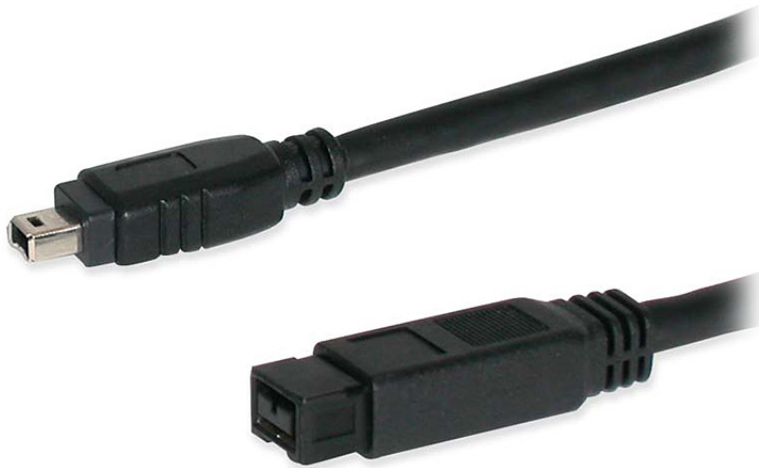

This 10ft 1394b FireWire cable provides one FireWire 800 9-pin male connector and one FireWire 4-pin male connector, allowing you to connect your FireWire 400 devices to your FireWire 800 ports - ensuring that your high speed digital storage and video capture applications will be running at their peak.

Expertly designed to provide a high quality, long-lasting FireWire connection, the 1394b FireWire (4 pin to 9 pin) cable is backed by StarTech.com's Lifetime Warranty.

Applications and Solutions

- Connect multiple FireWire devices together
- Ideal for Mass storage, Digital Video (DV), Digital Audio, Digital Cameras, Printers, Scanners, Home entertainment and other Networking products

Features

- Compatible with all 1394a & 1394b PC FireWire, Apple FireWire, and Sony iLink devices
- Compliant with 1394a & 1394b standards
- Fast data transfer rate of up to 800 Mbits/sec
- Highest quality shielding protects from EMI (electromagnetic interference) noise
- Hot Pluggable feature allows swapping of live devices without turning off your computer
- Supports a daisy-chain of up to 63 fireWire devices
- Twisted Pair Construction

Technical Specifications

- Warranty: Lifetime warranty
- Connector A: 1 - Firewire 800 9 pin Male
- Connector B: 1 - Firewire 4 pin Male
- Color: Black
- Product Length: 10 ft [3.05 m]
- Maximum Cable Length: 14 ft [4.27 m]
- Carton Quantity: 120
- Shipping (Package) Weight: 0.29 lb [0.13 kg]
- Cable Length: 10 Feet (3 Meters)
- Connector A: : 1394b 9 pin Male
- Connector B: 1394a 4 pin Male
- Compliant Standard: IEEE 1394a & 1394b
- Color: Black

