


2m Multimode 50/125 Duplex Fiber Patch Cable LC - SC
StarTech ID: 50FIBLCSC2

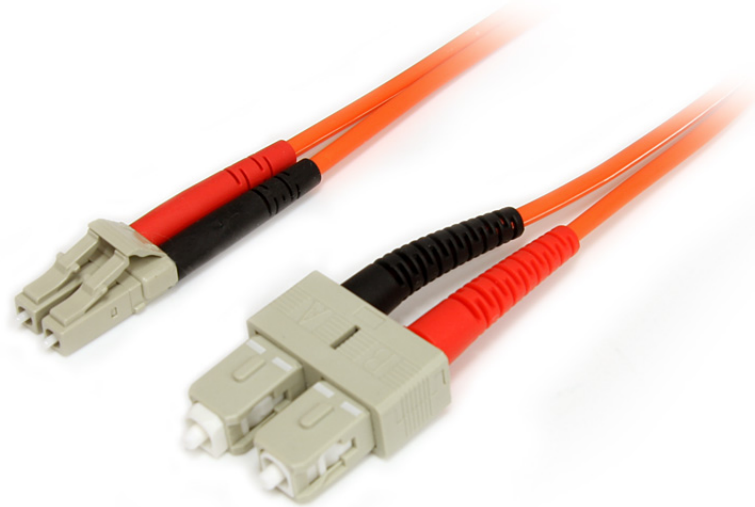

The 50FIBLCSC2, 2-meter (6.6ft) Multimode 50/125 Duplex Fiber Patch Cable is terminated with one LC (male) connector and one SC (male) connector, to provide the necessary connection between fiber networking devices for high-speed, long distance networks.

Ensuring optimal data transfers and network stability, 50/125-micron cables offer nearly three times the bandwidth of 62.5/125-micron cables, so your data will be transferred at higher rates over longer distances.

Each Duplex 50/125 Multimode Fiber Patch Cable is individually tested and certified to be within acceptable optical insertion loss limits for guaranteed compatibility and 100% reliability.

Applications and Solutions

- Used by long distance networks with mission critical data
- Telecommunication / Data communication
- Broadband systems
- Ideal solution for data applications requiring high speed data transmission

Features

- Attenuation loss meets or exceeds industry standards
- Immune to electricity interference
- Connectors offer greater durability in resisting pulls, strains, and impacts during cable installation and maintenance

Technical Specifications

- Warranty: Lifetime
- Cable Length: 6.56 ft [2 m]
- Fiber Size: 50/125
- Product Length: 6.56 ft [2 m]
- Carton Quantity: 80
- Shipping (Package) Weight: 0.07 lb [0.03 kg]

