


Adjustable Depth Fixed Server Rack Cabinet Shelf

StarTech ID: ADJSHELF

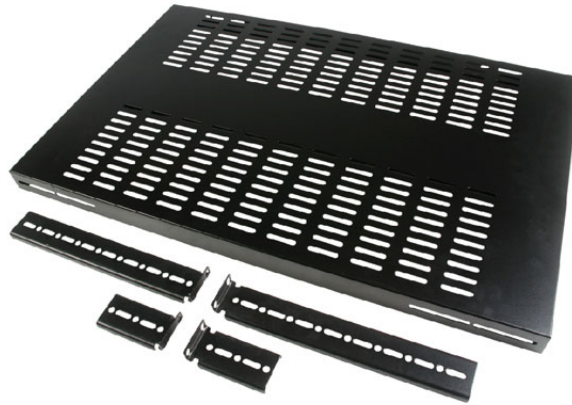

This Adjustable Depth Fixed Server Rack Cabinet Shelf offers a simple way to effectively organize mission critical computer hardware. Compatible with all 19in (wide) server racks/cabinets and can be adjusted from 19in to 38in as necessary.

Applications and Solutions

- For use with all 19" wide Server Racks and Cabinets
- Supply additional storage space for mission critical hardware.

Features

- adjustable mounting depth of 19" -38"
- Low cost adjustable shelf for most 19 inch wide cabinets and racks.
- Vented shelf plate to preserve airflow.
- Weight capacity up to 110 lbs (50 kgs).

Technical Specifications

- Warranty: 1 Year warranty
- Color: Black
- Product Height: 1.57 in [40 mm]
- Product Length: 27.56 in [700 mm]
- Carton Quantity: 1
- Shipping (Package) Weight: 11.93 lb [5.4 kg]
- Product Width: 17.52 in [445 mm]
- Weight Capacity: 110 lbs. (50 kg.)
- Mounting: Adjustable Side (front and rear)
- Min Mounting Depth: 495 mm
- Max Mounting Depth: 974 mm
- External Height : 1.57 in [40 mm]
- External Width : 18.9 in [480 mm]
- Internal Height: 1.57 in [40 mm]
- Internal Width: 17.56 in [446 mm]
- Internal Depth:: 27.56 in [700 mm]
- Maximum Mounting Depth:: 38.35 in [974 mm]
- Minimum Mounting Depth:: 19.49 in [495 mm]
- U Height: 1
- Product Weight: 155.32 oz [4400 g]

