


33 foot (10 meter) Active DVI Monitor Extension Cable

StarTech ID: *DVIAEXT10*

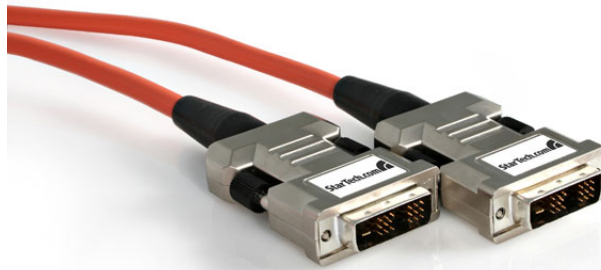

Extend the range of your DVI-enabled displays without losing signal quality! StarTech.com's Active DVI extension cables deliver crystal-clear digital images instantly – with a sharper, stronger signal than standard VGA monitor cables. Even over longer distances the quality of your digital images is preserved. Backed by StarTech.com's 2-year warranty and FREE lifetime tech support.

Applications and Solutions

- Conference Rooms
- Hospitals
- Educational Institutions
- Transportation Industry

Features

- High 1600 x 1200 pixel UXGA resolution
- Supports hot plugging of DVI display devices for quick setup
- Immune to electromagnetic and radio frequency interference
- High speed digital transmission up to 1.25 Gbits/sec
- Compliant with the DVI 1.0 standard

Technical Specifications

- Warranty: 2 Years
- Product Length: 32.8 ft [10 m]
- Maximum Analog Resolutions: 1280 x 1024
- Carton Quantity: 1
- Shipping (Package) Weight: 1.95 lb [0.88 kg]
- Fiber: H-PCF Graded multi-mode fiber
- Industry Standards: HDCP compliant
- Maximum Resolution: 1600 x 1200 pixels (UXGA)
- Note that this product is not intended for use with widescreen displays.

