


### 3 Port PCI Low Profile 1394a FireWire Adapter Card w Video Editing Kit

StarTech ID: PCI1394\_2LP

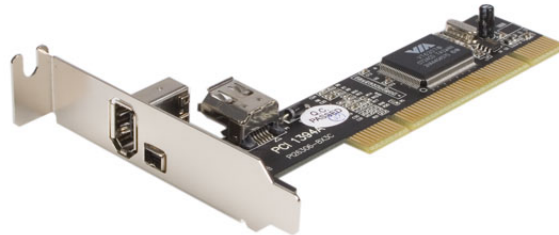

This 3 Port PCI Low-Profile/Half-Height 1394a FireWire Adapter Card turns a motherboard PCI slot into two external IEEE 1394a FireWire slots (1x6-pin, 1x4-pin), and provides an internal (6-pin) FireWire port that can be used in place of the external 6-pin connector - a cost-effective solution that lets you connect any FireWire 400 device to your desktop computer.

Compatible with either Mac or PC computers, the 1394a FireWire card can be installed in small/micro form factor computer cases, and includes both standard and low profile/half-height brackets for easy installation.

A practical solution for connecting iPods, MP3 players, portable drives, digital camcorders and more to your desktop computer, the FireWire 400 adapter card supports hot-swappable connectivity, allowing you to plug, unplug, and swap your FireWire peripherals with ease.

A versatile FireWire video editing solution, the adapter card can be installed in a PCI 5V or PCI-x 3.3V slot, and includes a copy of ULEAD's VideoStudio SE Basic video editing software (Windows only), making it easy to capture and edit video from your digital video camcorder.

## Applications and Solutions

- Digital camcorders
- Digital cameras
- DVD drives
- External CDR-CDRW drives
- iPods/MP3 players
- Portable hard drives
- Printers
- Scanners

## Features

- An internal connector allows for the easy connection of internal FireWire® peripherals
- High speed data transfer rates of up to 400 Mbits/sec.
- Hot swap capabilities allows you to connect or disconnect devices without turning off your computer
- Includes everything needed to edit your own home movies, add scene transitions and other effects with the included ULEAD® VideoStudio® SE software
- Packaged with low-profile/half-height mounting bracket attached, includes optional full-height/standard bracket

## Technical Specifications

- Warranty: Lifetime warranty
- Bus Type: PCI / PCI-X (5 / 3.3V)
- Chipset ID: VIA VT6307
- External Ports: 1 - FireWire 6-pin Female
- External Ports: 1 - FireWire 4-pin Female
- Internal Ports: 1 - FireWire 6-pin Female
- Maximum Data Transfer Rate: 400000000 Mbits/Sec
- Number of Ports: 2
- Carton Quantity: 50
- Industry Standards: PCI 2.1
- Industry Standards: IEEE 1394
- Industry Standards: IEEE 1394a
- Industry Standards: OHCI
- Shipping (Package) Weight: 0.49 lb [0.22 kg]
- OS Compatibility: Windows 98SE/ 2000/ XP(32/64bit)/ Server 2003(32/64bit)/ Vista(32/64bit)/ 7(32/64bit), Mac OS 10 and up, and Linux
- **Note:** The internal port and the top external port share the same connection, meaning that only one of these two ports can be used at a time. Configured with low bracket and standard bracket included

