


Value 1 Port PCI Parallel Adapter Card

StarTech ID: PC11P

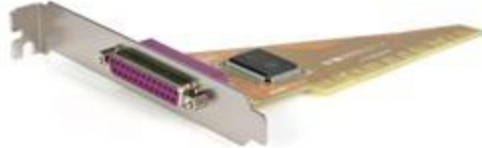

The PC11P value priced EPP/ECP parallel card adds one IEEE 1284 port to your PC, with data transfer speeds of up to 2.7 Mbps – up to 3 times faster than on-board parallel ports.

Installation is a breeze with plug and play support and drivers for Windows® 7, Vista, XP, ME, 2000, 98, 95, NT4, DOS® and Linux®. IRQ sharing and hot swapping capabilities guarantee convenient, hassle-free connections to any parallel peripheral.

Backed by a StarTech.com lifetime warranty and free lifetime technical support.

Applications

- Connects any parallel peripheral including printers, scanners, CD-R/RWs, Zip® drives, and memory card readers

Features

- Supports EPP, ECP, SPP and BPP
- Data transfer rates of up to 2.7 Mbits/sec maximizes the performance of your peripherals
- IRQ sharing eliminates conflicts between multiple cards
- Easy plug and play installation

Technical Specifications

Warranty	Lifetime
Ports	1
Bus Type	PCI / PCI-X (5 / 3.3V)
Card Type	Standard Profile
Port Style	Integrated on Card
Industry Standards	IEEE-1284
Chipset ID	Sunix - SUN1888
Connector Type(s)	1 - PCI / PCI-X (Universal 3.3 & 5V; 32-bit) Male
External Ports	1 - DB-25 (25 pin; D-Sub) Female
Maximum Data Transfer Rate	2.7Mbps
Supported Protocols	EPP, ECP, SPP, BPP
OS Compatibility	Windows® 8 (32/64bit), 7 (32/64), Vista(32/64), XP(32/64), ME, NT, 98, 95, DOS Linux
Microsoft WHQL Certified	Yes
Product Length	4.7 in [12 cm]
Product Height	2.2 in [55 mm]
System and Cable Requirements	Unused PCI slot
Shipping (Package) Weight	5.6 oz [160 g]
Included in Package	1 - 1 Port PCI Parallel Card
Included in Package	1 - Driver CD
Included in Package	1 - User Manual

Certifications, Reports and Compatibility

