


2 Port PCI Low Profile RS232 Serial Adapter Card with 16550 UART

StarTech ID: PCI2S550_LP

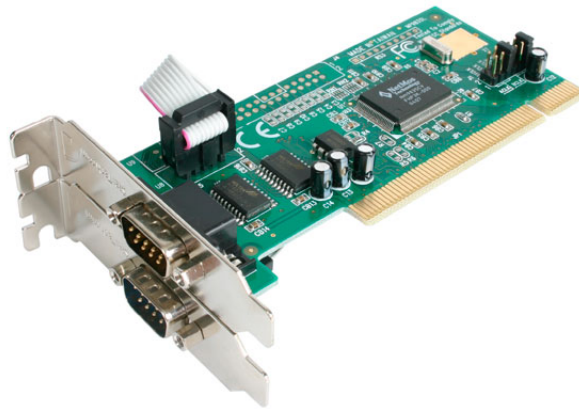

This 2 Port 16550 Serial Card can be installed in a PCI slot to add two serial ports - a cost-effective solution for connecting any new serial device or old legacy serial device, with data transfer rates of up to 115.2 Kbps. The serial card features a low profile bracket, suitable for installation in low profile/small form factor computer cases.

Perfect for connecting serial modems, POS devices, PDAs, digital cameras, printers, ISDN terminal adapters and more, to your system, the adapter card supports IRQ sharing and operates flawlessly with Windows® 7, Server 2008 R2, Vista, XP, Server 2003, 2000, ME, 98, 95, NT4, 3.1, DOS® and Linux®.

The card can be connected in minutes through simple plug and play installation and is backed by StarTech.com's lifetime warranty and FREE LIFETIME tech support.

Applications and Solutions

- **Manufacturing** (CNC machinery, process control equipment, bar code scanners, serial printers)
- **POS** (credit/debit card readers, receipt printers, bar code scanners, cash registers, scales)
- **Consumer** (modems, PDAs, digital cameras, printers)
- **Security** (UPS control, access key panels, video cameras, card readers, modems)
- **Casino** (video lottery terminals, slot machines)
- **Environmental Control** (lighting, temperature, clocks)
- **Healthcare** (patient monitoring equipment, nurses' stations, modems)
- **Hotel Front Desk** (serial printers, bar code scanners, keyboard, mouse, receipt printer, credit/debit card reader)
- **Hospitality/Restaurant** (credit card/debit card reader, serial printers)
- **ISDN Networking**

Features

- Supports the RS-232 serial interface
- 16 byte FIFO buffer ensures fast data transfer while multitasking
- IRQ sharing saves resources and eliminates conflicts
- OS Support: DOS, Windows 95/ 98SE/ ME/ XP(32/64bit)/ Vista(32/64bit)/ 7(32/64bit), and Linux

Technical Specifications

- Warranty: Lifetime warranty
- Bus Type: PCI (5 Volt)
- External Ports: 2 - DB 9-pin Serial Male
- Product Height: 0.79 in [20 mm]
- Product Length: 4.72 in [120 mm]
- Maximum Data Transfer Rate: 115000 Kbits/Sec
- Number of Ports: 2
- Carton Quantity: 50
- Shipping (Package) Weight: 0.31 lb [0.14 kg]
- Product Width: 2.17 in [55 mm]
- Ports: 2 x 16C550
- Communication Buffer: 16 Byte FIFO
- Chipset ID: MosChip MCS9835
- OS Compatibility: DOS, Windows 95/ 98SE/ 2000/ XP(32/64bit)/ Server 2003(32/64bit)/ Vista(32/64bit)/ 7(32/64bit)/ Server 2008 R2, Linux, and Mac OS 10.4.x and up
Windows XP Embedded/ POS Ready 2009/ Embedded System 2009 OS/ CE 5.0/ CE 6.0

