


2 Port PCI RS232 Serial Adapter Card with 16950 UART

StarTech ID: PCI2S950

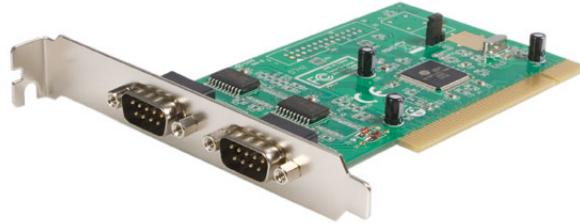

This high speed PCI Serial Card gives you two high performance 16C950 serial UART channels/ports for connecting any new or legacy serial peripheral, with data transfer rates of up to 115.2 Kbps.

The PCI-based RS232 Serial card is a cost-effective solution for connecting serial modems, POS devices, PDAs, digital cameras, printers, ISDN terminal adapters and more to your system, without having to upgrade peripherals for USB compatibility.

Installation is a breeze with support for Windows® Vista, XP, ME, 2000, 98, 95 and NT4. Plus, IRQ sharing and a PCI plug and play interface guarantee convenient, hassle-free connections.

This Serial PCI card is backed by StarTech.com's lifetime warranty and free lifetime technical support.

Applications and Solutions

- **Casino** (video lottery terminals, slot machines)
- **Consumer** (modems, PDAs, digital cameras, printers)
- **Environmental Control** (lighting, temperature, clocks)
- **Healthcare** (patient monitoring equipment, nurses' stations, modems)
- **Hospitality/Restaurant** (credit card/debit card reader, serial printers)
- **Hotel Front Desk** (serial printers, bar code scanners, keyboard, mouse, receipt printer, credit/debit card reader)
- **ISDN Networking**
- **Manufacturing** (CNC machinery, process control equipment, bar code scanners, serial printers)
- **POS** (credit/debit card readers, receipt printers, bar code scanners, cash registers, scales)
- **Security** (UPS control, access key panels, video cameras, card readers, modems)

Features

- IRQ sharing saves resources and eliminates conflicts
- Supports the RS-232 serial interface
- Full 128-byte receiver and transmitter FIFOs, fully adjustable IRQ trigger levels and automated flow-control

Technical Specifications

- Warranty: Lifetime warranty
- Bus Type: PCI (5 Volt)
- Chipset ID: Oxford - OX16PCI952
- External Ports: 2 - DB 9-pin Serial Male
- Maximum Data Transfer Rate: 250000 Kbits/Sec
- Number of Ports: 2
- Carton Quantity: 50
- Industry Standards: PCI 2.2
- Industry Standards: Power Management 1.1
- Shipping (Package) Weight: 0.35 lb [0.16 kg]
- General Specifications: 32-bit, 33 MHz PCI interface
- Data Transfer Rate: 460.8
- Communication Buffer: 128 Byte FIFO
- Operating Temperature: -20°C to 75°C (-4°F to 167°F)
- Storage Temperature: -40°C to 85°C (-40°F to 185°F)
- MTBF: 14,744,913 hours
- OS Compatibility: Windows 95/ 98SE/ ME/ 2000/ XP(32/64bit)/ Vista(32/64bit)/ 7(32/64bit)/ Server 2008 R2, and Linux

