


4 Port USB 2.0 3 Port IEEE 1394a PCI USB Firewire Combo Adapter Card

StarTech ID: PCI3UV22F

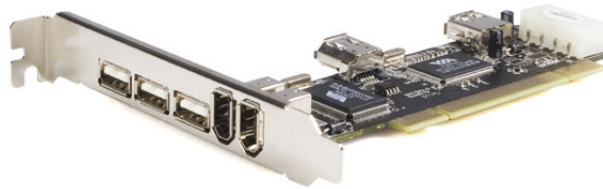

This USB and FireWire slot saver PCI card can be installed in an available PCI slot to provide three external USB 2.0 ports, one internal USB port, two external 6-pin IEEE 1394a FireWire ports and one internal FireWire (6-pin, 1394a) port.

A cost-effective solution, the USB/FireWire slot saver PCI card lets you connect FireWire or USB peripherals (e.g CD-RW/DVD-ROMs, external hard drives, video cameras, etc.), while taking up only one PCI expansion slot on the computer, in turn saving space in the computer for further card installations.

Supporting full high-speed USB (up to 480Mbps) and FireWire 400 (400Mbps) data transfer speeds, the adapter card lets you get the most from your USB or FireWire peripherals, ensuring seamless functionality with internally or externally connected peripherals.

Plus, the adapter is backward compatible with USB 1.1 devices, ensuring that even older USB peripherals can be connected.

Designed for long-lasting durability, the USB 2.0/FireWire 400 slot saver card is backed by StarTech.com's lifetime warranty and FREE LIFETIME tech support.

Applications and Solutions

- Connect to a wide range of USB 2.0/1.1 and IEEE-1394 FireWire® devices including CD-RW/DVD-ROMs, removable hard drives, video cameras, hubs, digital camcorders/cameras and MP3 players/iPods

Features

- Backward compatible with USB 1.1 devices
- Compliant with PCI specification 2.2
- Hot swap capabilities let you connect peripherals without rebooting
- Installs easily into a single PCI slot
- Three external (plus one internal) USB 2.0 ports with data transfer rates up to 480 Mbits/sec
- Two external (plus one internal) IEEE-1394 FireWire® ports with data transfer rates up to 400 Mbits/sec

Technical Specifications

- Warranty: Lifetime warranty
- Bus Type: PCI (5 Volt)
- Chipset ID: VIA VT6306
- Chipset ID: VIA VT6214L
- Connector Types: 3 - Firewire 6 pin Female
- Connector Types: 4 - USB A Female
- Maximum Data Transfer Rate: 480 Mbits/Sec
- Number of Ports: 3
- Carton Quantity: 50
- Shipping (Package) Weight: 0.42 lb [0.19 kg]
- Microsoft WHQL Certified: Yes
- External Ports:
 - USB: 3 x USB Type A Female
 - FireWire: 2 x 6 pin 1394A
- Internal Ports:
 - USB: 1 x USB Type A Female
 - FireWire: 1 x 6 pin 1394A
- Data Transfer Rates:
 - USB 2.0 Devices: Up to 480 Mbps
 - USB 1.1/1.0 Devices: Up to 12 Mbits/sec
 - IEEE 1394A Devices: Up to 400 Mbits/sec
- Bus Interface: PCI
- Industry Standards:

- PCI: Version 2.2
- FireWire: 1394 & 1394A
- USB: EHCI and OHCI Compliant
- System Requirements:
 - Minimum Processor Requirements: PC - Intel Pentium 2 at 400MHz or faster, Intel Celeron at 900MHz or faster, AMD Athlon of any speed

Mac - G3 original processor or faster

- OS Compatibility: Windows 2000/ XP(32/64bit)/ Server 2003(32/64bit)/ Vista(32/64bit)/ 7(32/64bit)/ Server 2008 R2, Linux, and Mac OS 10.2.6 or OS 10.2.8

