


4 Port PCI Dual Voltage WHQL Approved Serial Adapter Card with Legacy Port Remap Function
StarTech ID: PCI4S650DV

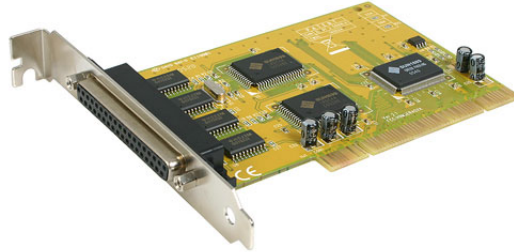

Get more out of your serial devices! StarTech.com's PCI4S650DV is a 4 port dual voltage serial card with WHQL certified drivers. Connecting legacy serial devices is no longer an issue as this card will remap to the necessary I/O address required by your device.

Great for connecting any new or old serial peripheral, with data transfer rates of up to 920 Kbits/sec. Dual Voltage compatibility allows you to install into a PCI or PCI-X slot. Perfect for connecting serial modems, POS devices, PDAs, digital cameras, printers, ISDN terminal adapters and more, to your system. Installation is a breeze with support for Windows® Vista, XP, Server 2003, 2000, ME, 98, NT4, 3.1, DOS® and Linux®. Guarantee convenient, hassle-free connections. Backed by StarTech.com's lifetime warranty and FREE LIFETIME tech support.

Applications and Solutions

- Casino (video lottery terminals, slot machines)
- Consumer (modems, PDAs, digital cameras, printers)
- Environmental Control (lighting, temperature, clocks)
- Healthcare (patient monitoring equipment, nurses' stations, modems)
- Hospitality/Restaurant (credit card/debit card reader, serial printers)
- Hotel Front Desk (serial printers, bar code scanners, keyboard, mouse, receipt printer, credit/debit card reader)
- ISDN Networking
- Manufacturing (CNC machinery, process control equipment, bar code scanners, serial printers)
- Manufacturing (CNC machinery, process control equipment, bar code scanners, serial printers)
- POS (credit/debit card readers, receipt printers, bar code scanners, cash registers, scales)
- Security (UPS control, access key panels, video cameras, card readers, modems)

Features

- Legacy port remap function allows you to re-assign I/O addresses and IRQ's for your legacy devices.
- Microsoft WHQL certified drivers
- 128K transmit/receive FIFO buffer helps improve overall system performance
- Dual voltage card supports both 64-bit(3.3V) and 32-bit(5V) PCI
- High speed serial data transfers up to 920Kbps (depending on Operating System)
- IRQ sharing eliminates IRQ conflicts

Technical Specifications

- Warranty: Lifetime warranty
- Supported Operating Systems for Remap Function: Microsoft DOS and Win9x/ME/NT 4.0
- Legacy Port Remap Addressing: 3F8, 3E8, 2F8, 2E8
- Bus Type: PCI / PCI-X (5 / 3.3V)
- Connector Types: 1 - DB37 Female
- Product Length: 4.72 in [120 mm]
- Number of Ports: 4
- Operating Temperature: 0-57
- Carton Quantity: 50
- Storage Temperature: 20-85
- Shipping (Package) Weight: 0.93 lb [0.42 kg]
- Product Weight: 2.47 oz [70 g]
- Microsoft WHQL Certified: Yes
- Product Width: 3.15 in [8 cm]
- Data Transfer Rate (max): 920 Kbits
- Compatible OS: DOS, Windows 95, 98, ME, NT; Windows XP (32-bit, 64-bit), Windows Vista (32-bit, 64-bit), Linux
- Cable: DB37 to 4 port DB9 breakout cable included. DB25 cable is optional accessory (DB254S650DV)
- Chipset: Sunix SUN1889

