


1 Port eSATA + 1 Port SATA PCI SATA Controller Card w/ LP Bracket

StarTech ID: PCIESATA2I

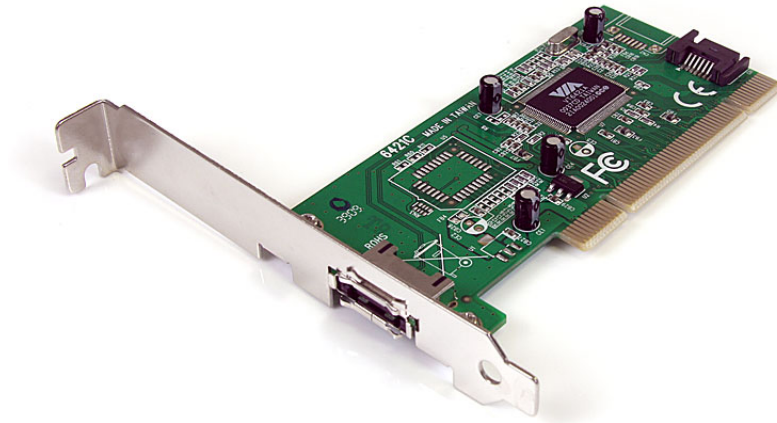

This PCI based SATA Controller Card allows you to turn a PCI slot into one internal SATA and one external SATA (eSATA) connection. Supporting SATA 150 hard drives, and data transfer rates of up to 1.5Gbps, this controller card is the perfect solution if you need an extra SATA port or want to externalize your storage.

Applications and Solutions

- Upgrade a PCI-based desktop with SATA and eSATA capabilities
- Add additional SATA capabilities to a desktop computer
- Add SATA capabilities to a low profile/small form factor (SFF) computer

Features

- 1 internal SATA port and 1 external eSATA port
- Large capacity drive support with 48-bit Logical Block Addressing (LBA)
- Fully compliant with the Serial ATA 1.0a specification, with transfer rates up to 1.5Gbps
- Independent 256-byte FIFOs (32 bit x 64 deep) per SATA channel
- Integrated PCI DMA engines
- Includes a low profile/half-height installation bracket

Technical Specifications

- Warranty: 2 Years
- Chipset ID: VIA VT6421
- Product Height: 0.79 in [20 mm]
- Product Length: 4.76 in [121 mm]
- Maximum Data Transfer Rate: 1.5 Gb/sec
- OS Compatibility: Windows 98SE/ 2000/ XP(32/64bit)/ Vista(32/64bit)/ 7(32/64bit)/ Server 2008 R2, and Linux
- Carton Quantity: 50
- Shipping (Package) Weight: 6.35 oz [180 g]
- Product Weight: 1.64 oz [46.6 g]
- Product Width: 2.13 in [54 mm]

