


7 Port PCI USB Card Adapter
StarTech ID: PCIUSB7

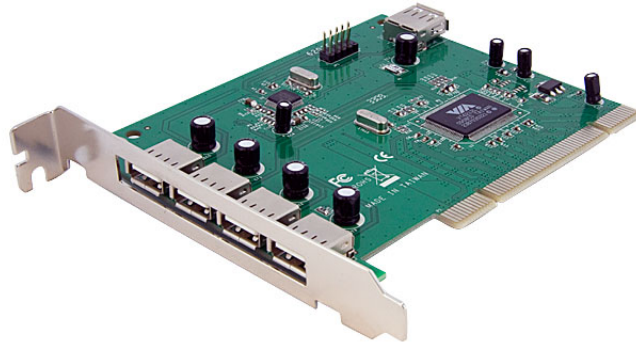

This PCI USB card adds seven USB 2.0 ports (1 internal USB A Female, 2 internal USB motherboard header, and 4 external USB A Female) to your PCI-capable PC.

Supported by popular operating systems including Windows 98SE/ME/2000/XP/Vista and Linux, the PCI USB 2.0 card is a versatile solution that lets you add USB 2.0 connections without having to upgrade the system motherboard.

An all-in-one solution, the PCI USB card supports USB 2.0 device connections for full data transfer speeds of up to 480Mbps, and is backward compatible with USB 1.1 devices (max. transfer rate 12Mbps), allowing you to connect any USB device to the computer without having to worry about compatibility issues.

Designed and constructed to provide long-lasting USB capability, the adapter card is backed by StarTech.com's free lifetime technical support.

Applications and Solutions

- Connect additional internal 5.25in and 3.5in bay card readers and hub
- Digital cameras
- DVD drives
- External CDR/RWs
- Flash card readers/writers
- Joysticks
- Mice and keyboards
- MP3 players
- PDAs
- Portable hard drives
- Printers
- Scanners
- Webcams

Features

- 40 times faster than USB 1.1
- Add 4 External (4 x USB A Female) and 3 Internal (1 x USB A Female, 2 x Motherboard Header)
- Backward compatible with USB version 1.1
- Compliant with Enhanced Host Controller Interface(EHCI) Specification Revision 1.0
- Compliant with PCI specification 2.2
- Compliant with Universal Host Controller Interface (UHCI) Specification Revision 1.1
- Compliant with USB Specification Revision 2.0
- Connect up to 127 devices by cascading multiple hubs
- Easy plug and play installation
- Provides 500mA of power per USB port
- Supports PCI-Bus power management Interface Specification release 1.1

Technical Specifications

- Warranty: 1 Year warranty
- Bus Type: PCI / PCI-X (5 / 3.3V)
- Chipset ID: Via Vectro - VT6212L
- External Ports: 4 - USB A Female
- Product Height: 0.79 in [20 mm]
- Internal Ports: 1 - USB A Female
- Internal Ports: 2 - 9 pin IDC (Motherboard Header) Male
- Product Length: 4.8 in [122 mm]
- Maximum Data Transfer Rate: 480 Mbps
- Number of Ports: 7
- Carton Quantity: 50
- Industry Standards: EHCI 2.0
- Industry Standards: OHCI 1.1
- Industry Standards: PCI 2.2
- Industry Standards: Power Management 1.1
- Shipping (Package) Weight: 6 oz [170 g]
- Product Weight: 2.51 oz [71 g]
- Microsoft WHQL Certified: Yes
- Product Width: 4.72 in [120 mm]
- OS Compatibility: Windows 98SE/ ME/ 2000/ XP(32/64bit)/ Vista(32/64bit)/ 7(32/64bit)/ Server 2008 R2, and Linux

