


43U 19in Knock Down Audio Video Rack
StarTech ID: RK4320AV

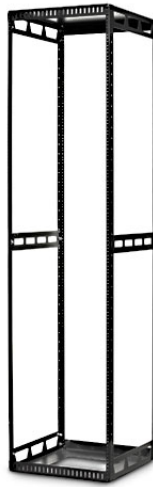

This high quality 43U 19in Knock Down AV Rack is designed to provide A/V professionals and integrators with a high-quality solution for housing audio-video equipment.

The AV rack provides 43U of cabinet space and accommodates AV components measuring up to 19in wide by 20in deep. Featuring 3mm steel rails and a highly durable design, the AV Rack features an impressive 400lb. storage capacity and provides optimized ventilation as well as easy access to cables and components.

Applications and Solutions

- Designed to provide A/V professionals and integrators with a high-quality solution for housing audio/video equipment
- Keep equipment secure and stored properly with the Converge A/V rack

Features

- 1/2" & 3/4" Conduit Knock Outs for simple cable configuration
- 19" Width provides broad compatibility with standard A/V component sizes
- 20" depth to fit most A/V components
- 3.0 millimeter threaded 10-32 front and rear rack rails
- Innovative bolt-together assembly
- Provides maximum durability and versatility
- Provides optimized ventilation as well as easy access to cables and components
- Solid construction allows for a maximum capacity of 400 lbs

Technical Specifications

- Warranty: 1 Year warranty
- Carton Quantity: 1
- Shipping (Package) Weight: 54.23 lb [24.54 kg]
- Color: Black
- Weight Capacity: 400 lb [181 kg]
- Frame Type: : Steel
- Casters:: Optional
- External Height : 78.75 in [2000.25 mm]
- External Width : 19.25 in [488.95 mm]
- External Depth : 19.75 in [501.65 mm]
- Internal Height: 75.13 in [1908.18 mm]
- Internal Width: 17.75 in [450.85 mm]
- Minimum Mounting Depth:: 19.75 in [501.65 mm]
- U Height: 43
- Height with Casters:: 81.63 in [2073.28 mm]
- Industry Standards: EIA RS310-C

