


## 50cm Internal Mini-SAS Cable SFF-8087 To SFF-8087 w/ Sidebands

StarTech ID: SAS878750

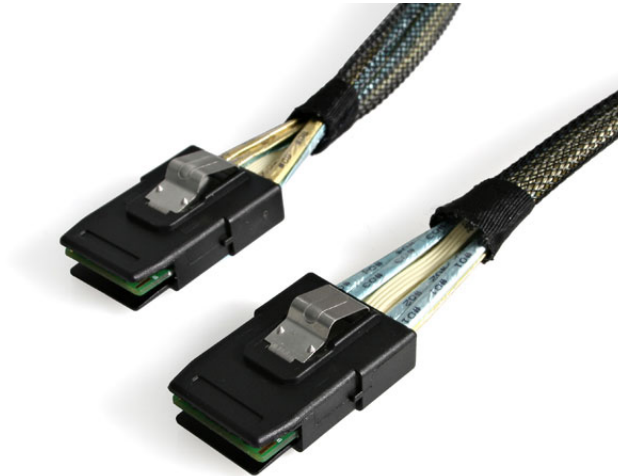

StarTech.com's internal Mini-SAS cable (with Sidebands) features SFF-8087 connectors, helping you transmit, manage and protect critical data and digital content.

Designed to provide durable connectivity for high-performance networks, servers, workstations and desktops, this Mini-SAS cable is backed by StarTech.com's Lifetime Warranty.

### Technical Specifications

- Warranty: Lifetime warranty
- Carton Quantity: 50
- Shipping (Package) Weight: 0.07 lb [0.03 kg]
- Connectors: 36 pin cable plug to 36 pin cable plug
- Hood: Nylon
- P.C.B: FR4, 4 Layers
- Latch: Stainless Steel
- General Specifications: Internal, with sideband
- Impedance: 100+5 ohm (differential TDR)
- Capacitance: 49pF/ M Nominal
- Prop Delay: 4.9pF/ M Nominal

- Skew (within pair) : <10ps/ 1M (TDT method drains grounded, 3M sample)
- Attenuation: 3.00 dB/M @ 4.50 GHz

