


6 Drive Internal U320 HPDB68 Male SCSI Terminated Cable

StarTech ID: *SCSI320INT7*

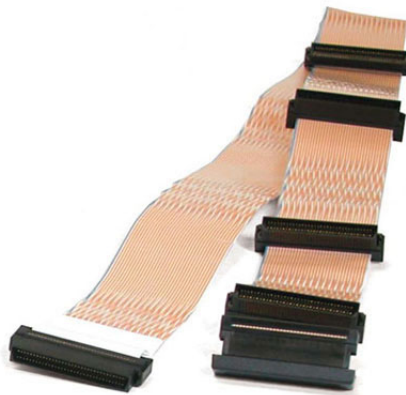

This LVD/SE terminated internal SCSI cable lets you connect 6 U320 hard drives to a host controller. Perfect for high-end workstations or servers with U320 SCSI drives, this 68-pin "twist-n-flat" ribbon cable is fully laminated and designed to strengthen signal integrity and offer reduced crosstalk on all pairs.

The SCSI cable features plastic pull-tabs make it easy to disconnect the cable without damage to the connectors or your drives, and includes a built-in LVD/SE terminator.

Applications and Solutions

- For use in servers and storage subsystems
- High-end workstations
- Ideal when connecting 6 U320 hard drives to a host controller
- Wiring design ensures 100% compatibility with SCSI U320 & U160 Hard Drives

Features

- Each connector includes a label for easy identification
- Meets current SCSI specifications and ensures maximum performance and data integrity
- Orange color twisted pair construction
- Specially designed to improve system airflow and routability

Technical Specifications

- Warranty: Lifetime warranty
- Connector A: 1 - IDC 68 pin Half-Pitch Male
- Connector B: 6 - IDC 68 pin Half-Pitch Male
- Color: Brown
- Maximum Cable Length: 19.68 ft [6 m]
- Carton Quantity: 50
- Shipping (Package) Weight: 0.4 lb [0.18 kg]
- Hard Drive: Supports SCSI U320 & 160 Hard Drives
- Number of Hard Drives: 2
- Cable Type: Flat and Twisted
- Connectors: Half Pitch DB68 Male & 6 Half Pitch DB68 Male
- System to Device 1: 21" (530mm)
- Device 1-2: 5" (127mm)
- Device 2-3: 5" (127mm)
- Device 3-4: 5" (127mm)
- Device 4-5: 5" (127mm)
- Device 5-6: 5" (127mm)