

RK120D

Installation Guide




Packaging Contents

- 2 x Side Posts
- 2 x Bottom Braces
- 4 x Assembly Screws
- 20 x M5 Cage Nuts
- 20 x M5 Panel Screws

Assembly

1. Once the packaging contents are removed, make sure all of the components are present.

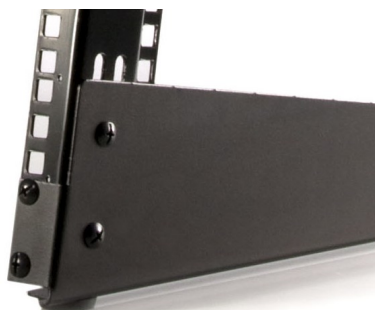

2. Locate the 2 side posts and the 2 bottom braces, and align the screw holes on the wide end of the bottom braces, with the screw holes located at one end of the side posts. Use the provided assembly screws to attach them.

3. Use the provided square cage nuts and screws to mount rack mountable equipment into the desktop rack, one post at a time.

Specifications

Description	12U Open Frame Desktop Rack
Colour	Black
Material	SPCC
Dimensions	292.0 mm x 504.0 mm x 584.0 mm
Net Weight	2.6 kg
Standards	EIA-310D
Certifications	UL/CE

Warranty Information

This product is backed by a one year warranty.

In addition, StarTech.com warrants its products against defects in materials and workmanship for the periods noted, following the initial date of purchase. During this period, the products may be returned for repair, or replacement with equivalent products at our discretion. The warranty covers parts and labor costs only. StarTech.com does not warrant its products from defects or damages arising from misuse, abuse, alteration, or normal wear and tear.

Limitation of Liability

In no event shall the liability of StarTech.com Ltd. and StarTech.com USA LLP (or their officers, directors, employees or agents) for any damages (whether direct or indirect, special, punitive, incidental, consequential, or otherwise), loss of profits, loss of business, or any pecuniary loss, arising out of or related to the use of the product exceed the actual price paid for the product. Some states do not allow the exclusion or limitation of incidental or consequential damages. If such laws apply, the limitations or exclusions contained in this statement may not apply to you.