


# RKLCDBK Installation Guide


## Packaging Contents

- 1 x RKLCDBK LCD bracket
- 4 x M4 Truss Head Screws
- 4 x M4 Flat Head Screws
- 4 x M4 Flat Washers
- 8 x M5 Cabinet Screws
- 1 x Installation Guide

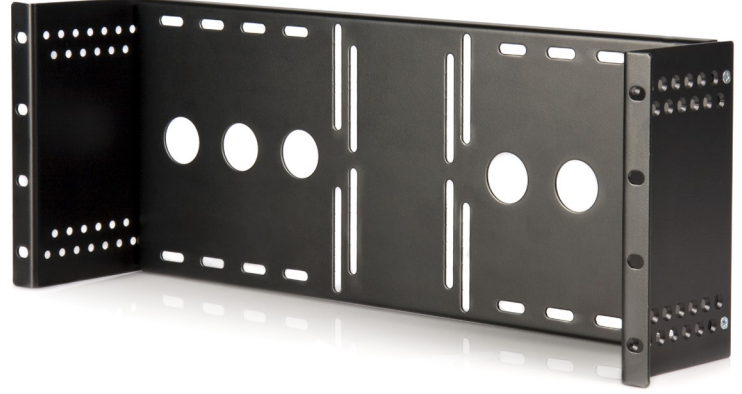

## Installation

1. Place the LCD monitor face-down, so the VESA MIS-D mounts are facing up.
2. Remove the rack mounting brackets from either side of the RKLCDBK and place it on top of the LCD monitor.
3. Align the screw mounting points on the monitor with the adjustable mounting points on the RKLCDBK. Use the M4 washers and screws to secure the monitor to the RKLCDBK.

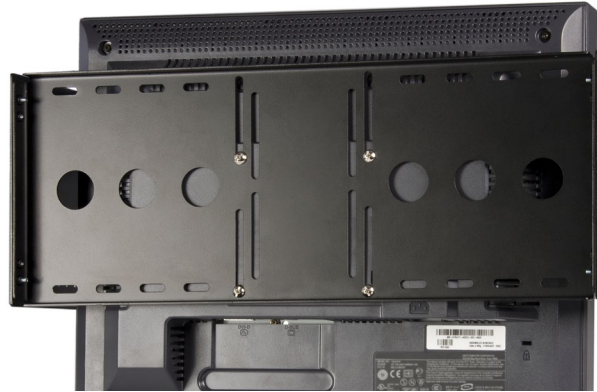


4. Attach the rack mounting brackets to either side of the RKLCDBK.
5. Mount the RKLCDBK into a 19" wide rack, using the provided M5 cabinet screws. \*if the rack does not use M5, then other cabinet screws will need to be obtained.



## Alternative Mounting

If mounting into an open rack or cabinet where the doors will not be an obstruction, the RKLCDBK can be mounted so the monitor/display sits outside of the rack/cabinet frame. Any sized monitor/display can be mounted that uses the VESA MIS-D 75/100 mounts.

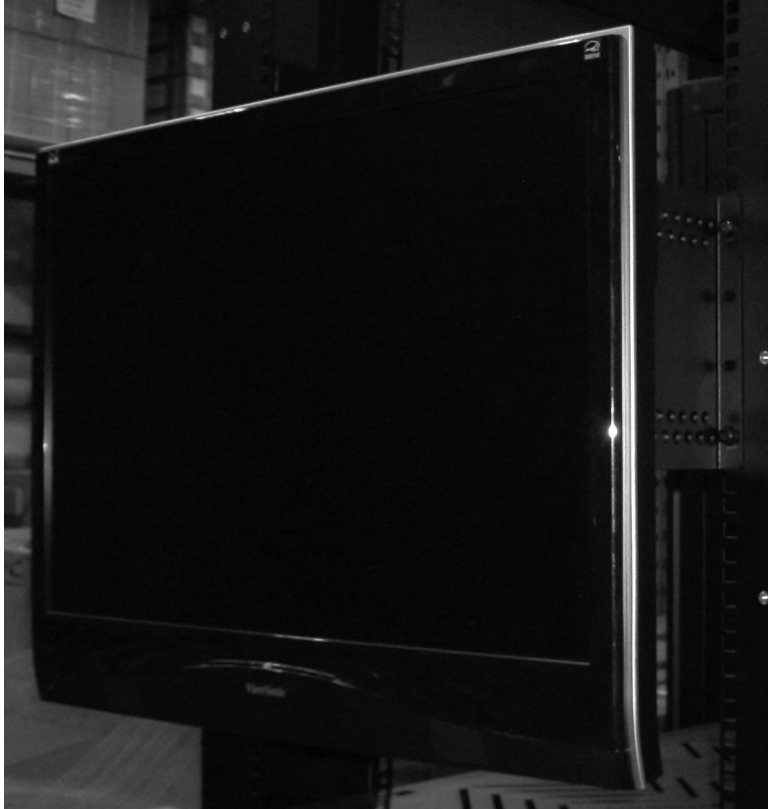

## Specifications

Description	LCD Monitor Universal VESA Mounting Bracket for 19" Racks/Cabinets
Height	4U
Material	SPCC/HC
Colour	Black
Dimensions	482.0 mm x 177.0 mm x 107.5 mm
Net Weight	1.7 kgs
Standards	EIA-310D, MIS-D 75, MIS-D 100

**\*Compatible with 19" or smaller monitors. 17" or larger widescreen monitors are not compatible.**

### FCC Compliance Statement

This equipment has been tested and found to comply with the limits for a Class B digital device, pursuant to part 15 of the FCC Rules. These limits are designed to provide reasonable protection against harmful interference in a residential installation. This equipment generates, uses and can radiate radio frequency energy and, if not installed and used in accordance with the instructions, may cause harmful interference to radio communications. However, there is no guarantee that interference will not occur in a particular installation. If this equipment does cause harmful interference to radio or television reception, which can be determined by turning the equipment off and on, the user is encouraged to try to correct the interference by one or more of the following measures:

- Reorient or relocate the receiving antenna.
- Increase the separation between the equipment and receiver.
- Connect the equipment into an outlet on a circuit different from that to which the receiver is connected.
- Consult the dealer or an experienced radio/TV technician for help.

### Use of Trademarks, Registered Trademarks, and other Protected Names and Symbols

This manual may make reference to trademarks, registered trademarks, and other protected names and/or symbols of third-party companies not related in any way to StarTech.com. Where they occur these references are for illustrative purposes only and do not represent an endorsement of a product or service by StarTech.com, or an endorsement of the product(s) to which this manual applies by the third-party company in question. Regardless of any direct acknowledgement elsewhere in the body of this document, StarTech.com hereby acknowledges that all trademarks, registered trademarks, service marks, and other protected names and/or symbols contained in this manual and related documents are the property of their respective holders.

### Technical Support

StarTech.com's lifetime technical support is an integral part of our commitment to provide industry-leading solutions. If you ever need help with your product, visit [www.startech.com/support](http://www.startech.com/support) and access our comprehensive selection of online tools, documentation, and downloads.

### Warranty Information

This product is backed by a lifetime warranty.

In addition, StarTech.com warrants its products against defects in materials and workmanship for the periods noted, following the initial date of purchase. During this period, the products may be returned for repair, or replacement with equivalent products at our discretion. The warranty covers parts and labor costs only. StarTech.com does not warrant its products from defects or damages arising from misuse, abuse, alteration, or normal wear and tear.

### Limitation of Liability

In no event shall the liability of StarTech.com Ltd. and StarTech.com USA LLP (or their officers, directors, employees or agents) for any damages (whether direct or indirect, special, punitive, incidental, consequential, or otherwise), loss of profits, loss of business, or any pecuniary loss, arising out of or related to the use of the product exceed the actual price paid for the product. Some states do not allow the exclusion or limitation of incidental or consequential damages. If such laws apply, the limitations or exclusions contained in this statement may not apply to you.