


## 180° Cat 6 Keystone Jack - RJ45 Ethernet Cat6 Wall Jack White - 110 Type

Product ID: C6KEY110SWH

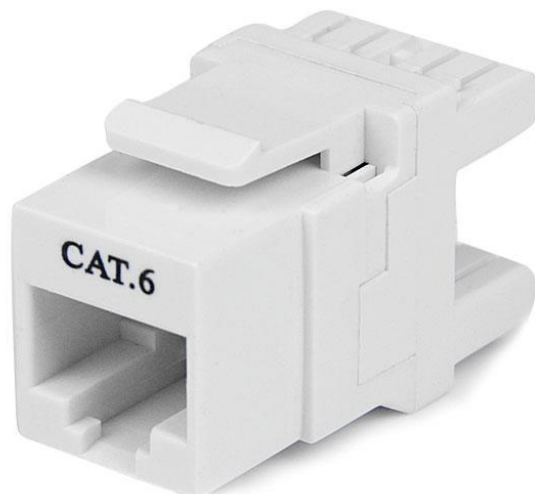

The C6KEY110SWH Cat6 Keystone Jack is designed to snap into wall plates, patch panels, and surface connection boxes for quick, seamless deployment.

Meeting and exceeding the international standard ISO / IEC 11801 and the ANSI/TIA-568-C.2 requirements, this RJ45 keystone jack provides the perfect solution for your Ethernet networks.

Durably constructed of only top quality materials, this Cat6 wall jack is backed by StarTech.com's 2 year warranty.

### Certifications, Reports and Compatibility



### Applications

- Suitable for applications that use 23-26 AWG solid state and stranded network cables
- 1000BASE-T Gigabit Ethernet, 100BASE-TX Fast Ethernet, 10BASE-T Ethernet applications
- ATM-25/ATM-51/ATM-155 network connections
- 100 VG-AnyLan network connections
- TR-4/TR-16 Active/TR16 Passive network connections

### Features

- The wall jack features a high-impact, flame retardant (UL 94V0) plastic housing
- Meets and exceeds the international standard ISO / IEC 11801 and the ANSI/TIA-568-C.2 requirements
- Dual-type IDC connectors, situated 180° relative to the RJ45 ports, terminated using 110-type punch tool
- Color coded for both T568A and T568B installations

	Warranty	2 Years
<b>Connector(s)</b>	Connector Type(s)	1 - RJ-45 Female
<b>Physical Characteristics</b>	Color	White
	Product Height	0.9 in [22 mm]
	Product Length	1.4 in [35 mm]
	Product Weight	0.2 oz [7 g]
	Product Width	0.7 in [17 mm]
<b>Packaging Information</b>	Package Quantity	1
	Shipping (Package) Weight	0 lb [0 kg]
<b>What's in the Box</b>	Included in Package	1 - 180° Cat 6 RJ45 Keystone Jack White - 110 Type

Product appearance and specifications are subject to change without notice.