


Fiber Optic Cable - Multimode Duplex 62.5/125 - LSZH - LC/SC - 1 m

Product ID: FIBLCSC1

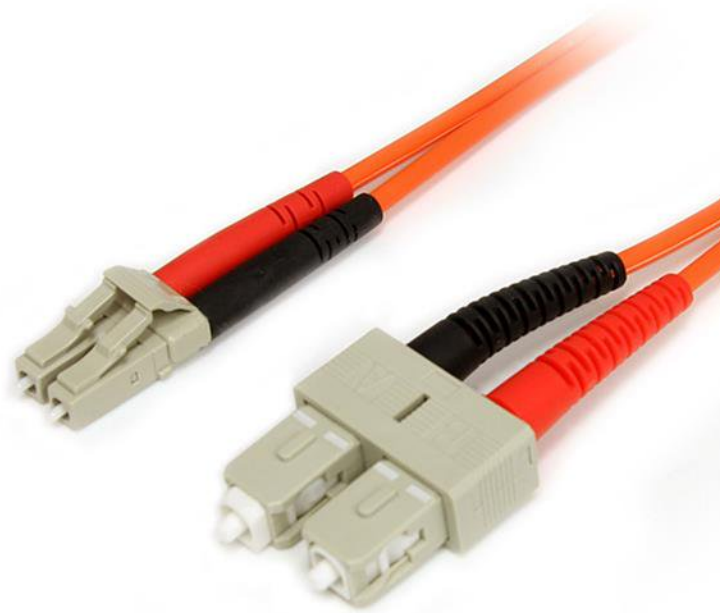

The FIBLCSC1 1-meter (3.2ft) Multimode 62.5/125 Duplex Fiber Patch Cable is terminated with one LC (male) connector and one SC (male) connector, to provide the necessary connection between fiber networking devices for high-speed, long distance networks.

This LC-SC patch cable is housed in a LSZH (Low-Smoke, Zero-Halogen) flame retardant jacket, to ensure minimal smoke, toxicity and corrosion when exposed to high sources of heat, in the event of a fire. Making it ideal for use in industrial settings, central offices and schools, as well as residential settings where building codes are a consideration.

To ensure optimum performance, our multimode fiber duplex cable is individually tested and certified to be within acceptable optical insertion loss limits for guaranteed compatibility and 100% reliability.

Backed by Lifetime Warranty, our LC-SC Multimode Fiber Patch cable is guaranteed to provide long-lasting dependability, and top quality performance.

Certifications, Reports and Compatibility



Applications

- Ideal solution for data applications requiring high speed data transmission
- Broadband systems
- Telecommunication/Data communication
- Used by long distance networks with mission critical data

Features

- Attenuation loss meets or exceeds industry standards
- LSZH (Low-Smoke, Zero-Halogen) cable jacket
- Immune to electrical interference

| | | |
|---------------------------------|----------------------------|------------------------------------------------------------|
| Hardware | Warranty | Lifetime |
| | Fiber Size | 62.5/125 |
| | Fire Rating | LSZH Rated (Low Smoke Zero Halogen) |
| Performance | Cable Rating | 1Gbps / 10Gbps |
| | Fiber Classification | OM1 |
| | Maximum Data Transfer Rate | 10Gbps |
| | Type | Multi Mode |
| Connector(s) | Connector A | 1 - Fiber Optic LC Duplex Male |
| | Connector B | 1 - Fiber Optic SC Duplex Male |
| Environmental | Humidity | 0~90% RH |
| | Operating Temperature | -20°C to 60°C (-4°F to 140°F) |
| | Storage Temperature | -20°C to 60°C (-4°F to 140°F) |
| Physical Characteristics | Cable Length | 3.3 ft [1 m] |
| | Color | Orange |
| | Product Length | 3.3 ft [1 m] |
| | Product Weight | 0.9 oz [26 g] |
| Packaging Information | Shipping (Package) Weight | 1.2 oz [35 g] |
| What's in the Box | Included in Package | 1 - 1m Multimode 62.5/125 Duplex Fiber Patch Cable LC - SC |

Product appearance and specifications are subject to change without notice.