

## Flat-Screen TV Ceiling Mount - 1.8' to 3' Short Pole - For 32" to 70" TVs - Full Motion

Product ID: FPCEILPTBSP



Save space and create the ultimate viewing environment for your flat-screen television, by suspending it from the ceiling. This flat-screen TV ceiling mount supports VESA mount compatible TVs 32" to 70" in size. For maximum viewing versatility, the ceiling mount makes it easy to adjust the distance from the ceiling and offers a full-motion design that lets you change your screen position and angle.



## Mount your TV in a prominent place, while saving space

The ceiling TV mount lets you mount your flat-panel LCD, LED or plasma TV in a prominent and comfortable viewing area while saving wall, desk and floor space. It's ideal for use in corporate boardrooms, hotel lobbies, restaurants, bars and meeting spaces.

The heavy-duty steel TV ceiling mount is compatible with a wide selection of TVs, able to securely support a 32" to 70" display, with a weight capacity of up to 110 lb. (50 kg). To keep the cables concealed and organized, you simply run the cables through the cable management channel inside of the pole, exiting near the top.

## Adjust the distance from the ceiling


With an adjustable pole length, the telescopic-style pole makes it easy to mount your display at the desired distance from the ceiling and works well with a range of ceiling heights. The robust steel pole can extend from a minimum of 22" to 35.8" (560 mm to 910 mm) at maximum length, with a total lift (height extension) of 13.7" (350 mm).

## Swivel the ceiling TV mount to suit your ceiling type

The flat-screen TV ceiling mount is designed to accommodate a wide variety of ceiling types. The ceiling mount swivels, so you can adjust the mount to work with virtually any type of ceiling for level viewing, including sloped ceilings (up to 60°), and pitched or horizontal (flat) ceilings. The extension pole also swivels + 180° / - 180° for optimum viewing.

## Adjust your display for the ideal viewing angle

You can adjust your flat-screen TV to create a comfortable viewing angle, by tilting it (up to -25°) down towards your audience for optimum visibility. The full-motion mount lets you tilt or swivel your display around the pole, without using tools. The ceiling mount also features a 360° pan, which makes it easy to set up for viewing from any direction you choose.

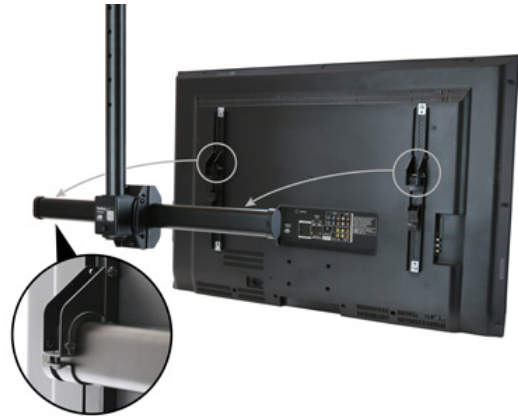

### Easy and secure setup

The hook-and-mount design of the TV ceiling mount makes setup fast and easy. You simply attach the vertical brackets, with built-in hooks, to the back of your TV. Once the brackets are attached, you can hang your TV securely onto the ceiling mount. The preset leveling adjustments ensure ideal positioning after hanging.

The FPCEILPTBSP is backed by a StarTech.com 2-year warranty and free lifetime technical support.

### Certifications, Reports and Compatibility



### Applications

- Safely and securely suspend your flat-screen TV from the ceiling for easy viewing in boardrooms, lobbies, lecture halls, classrooms and meeting spaces
- Keep your guests informed or entertained, ideal in hotels, restaurants and other hospitality venues
- Save wall and desk space in your home theater

### Features

- Save space by suspending your 32" to 70" flat-screen TV from the ceiling
- Ceiling TV mount swivels + 60° / - 60° to adjust to sloped or level ceilings
- Heavy-duty steel ceiling mount supports up to 110 lb. (50 kg)
- Full-motion mount allows you to tilt the display down 25° or swivel + 180° / - 180° around the pole, without using tools
- Min-max pole length extension of 22" to 35.8" (560 to 910 mm)
- Preset leveling adjustments ensure ideal positioning after hanging
- Supports VESA Mount compliant TVs: 200x200, 300x300, 400x200, 400x400, 600x400 mm
- Cable management channel inside pole

<b>Hardware</b>	Warranty	2 Years
	# of Displays Supported	1
	Cable Management	Yes
	Mounting Options	Ceiling Mount
	VESA Hole Pattern(s)	200x200 mm
		300x300 mm
		400x200 mm
400x400 mm		
600x400 mm		
Wallmountable	No	
<b>Performance</b>	Anti-theft	No
	Display Rotation	360°
	Height Adjustment	Yes
	Maximum Display Size	70"
	Maximum Height	35.8 in [910 mm]
	Minimum Display Size	32"
	Minimum Height	22 in [560 mm]
	Mounting Surface Thickness	560 mm to 910 mm
	Swivel / Pivot	+180° to -180°
	Tilt	+0° / -25°
	Video Wall	No
Weight Capacity (Per Display)	110.5 lb [50 kg]	
<b>Physical Characteristics</b>	Color	Black
	Enclosure Type	Steel
	Product Height	45.3 in [1150 mm]
	Product Length	26.8 in [680 mm]
	Product Weight	11.1 lb [5 kg]
	Product Width	17.1 in [435 mm]
<b>Packaging Information</b>	Shipping (Package) Weight	15.2 lb [6.9 kg]
<b>What's in the Box</b>	Included in Package	1 - ceiling mount and pole

- 1 - extension pole
- 2 - vertical brackets
- 1 - horizontal bracket
- 2 - bolts
- 2 - nuts
- 1 - wrench
- 1 - hex key
- 1 - mounting template
- 4 - M5x14 mm screws
- 4 - M6x14 mm screws
- 4 - M6x30 mm screws
- 4 - M8x30 mm screws
- 4 - M8x50 mm screws
- 4 - rectangular washers
- 8 - small spacers
- 8 - large spacers
- 4 - 6.3x55 mm screws
- 4 - concrete anchor
- 4 - circular washers
- 1 - instruction manual

---

Product appearance and specifications are subject to change without notice.