


Full-Motion TV Wall Mount - Premium - Silver

Product ID: FPWARPS

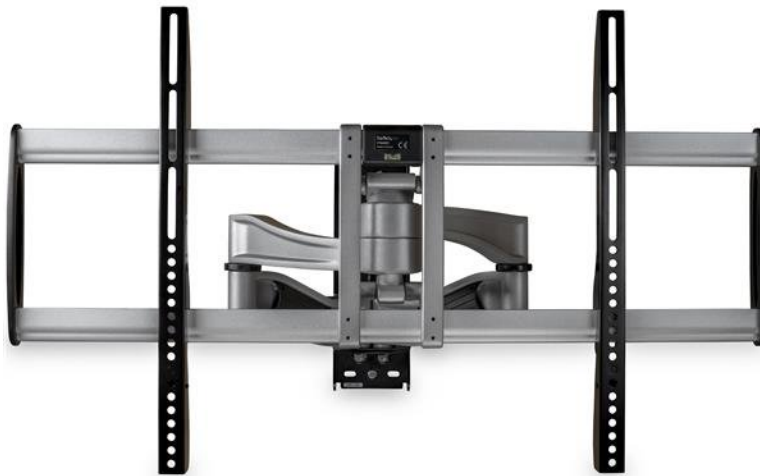

Strong and sleek, this full-motion TV wall mount lets you free up space by wall-mounting your 32" to 75" TV, and adjust it to the right viewing position with ease.

Smooth Full-Motion Adjustability

Once it's installed, the flat-screen TV wall mount is simple to adjust without using tools. You can extend the arms with ease to position your TV anywhere from 4.1" to 21.6" (105 to 550 mm) away from the wall. The TV mount swivels +/-60 degrees and tilts +/-15 degrees for optimum viewing.

Sleek Design

This premium television wall mount beautifully combines form and function. Designed to provide an impressive appearance in every position, the premium black and silver design makes it ideal in a company lobby or hallway, information kiosk, or living space. With the arms extended, the protective covers provide a tidy, professional look. The cable-management channel inside the arms keeps cables neatly tucked away.

Durable Construction

Engineered with steel and aluminum, the robust TV mount securely supports a TV with a maximum weight capacity of 187.4 lb. (85 kg).

FPWARPS is backed by a StarTech.com 5-year warranty and free lifetime technical support.

Certifications, Reports and Compatibility



Applications

- Wall-mount your TV in a boardroom, lobby, lecture hall, classroom or meeting space
- Keep guests informed or entertained in hotels, restaurants and other hospitality venues
- Save space by wall-mounting your TV in your home theater or living room

Features

- Save space by wall-mounting your 32" to 75" TV
- Easy adjustment with full-motion articulating arms
- Swivels +/-60° and tilts +/-15° for ideal viewing
- Arms extend from 4.1" to 21.6"(105 to 550 mm) from the wall
- Sleek and robust steel and aluminum construction (supports up to 187.4 lb./ 85 kg)

Hardware	Warranty	5 Years
	# of Displays Supported	1
	Cable Management	Yes
	VESA Hole Pattern(s)	200x200 mm
		300x300 mm
		400x200 mm
		400x400 mm
		600x400 mm
		700x400 mm
800x400 mm		
Wallmountable	Yes	
Performance	Display Tilt	+ 15° / - 15°
	Maximum Display Size	75"
	Maximum Distance to Wall	21.65" (550 mm)
	Minimum Display Size	32"
	Minimum Distance to Wall	4.13" (105 mm)
	Swivel / Pivot	+ 60° / - 60°
	Video Wall	No
	Weight Capacity (Per Display)	187.9 lb [85 kg]
Physical Characteristics	Color	Black & Silver
	Enclosure Type	Steel, Aluminum and Plastic
	Product Height	20.6 in [52.4 cm]
	Product Length	34.1 in [86.5 cm]
	Product Width	20.5 in [52 cm]
	Weight of Product	22.8 lb [10.3 kg]
Packaging Information	Package Height	5.5 in [14 cm]
	Package Length	35.8 in [91 cm]
	Package Width	18.1 in [46 cm]
	Shipping (Package) Weight	28 lb [12.7 kg]
What's in the Box	Included in Package	1 - TV Wall-Mount Assembly

- 2 - Vertical Brackets
- 1 - 6 mm Hex Key
- 2 - Vertical Bracket Screws
- 8 - Concrete Anchors
- 8 - Wall Screws
- 4 - M4 x 12 mm Screws
- 4 - M4 x 18 mm Screws
- 4 - M5 x 12 mm Screws
- 4 - M6 x 12 mm Screws
- 4 - M6 x 18 mm Screws
- 4 - M8 x 12 mm Screws
- 4 - Flat Washers
- 4 - M8 x 18 mm Screws
- 1 - User Manual

Product appearance and specifications are subject to change without notice.