


Full-Motion TV Wall Mount

Product ID: FPWARTB2

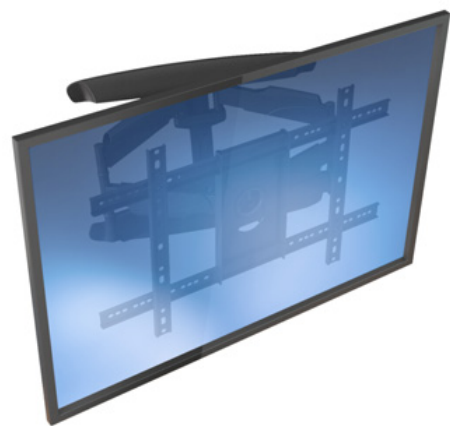

Maximize space while creating an impressive display. This full-motion TV wall mount supports flat-screen TVs from 32" to 70" in size, with a weight capacity of 99 lb. (45 kg).



Save Space

Mount your flat-screen TV in a location that's convenient for visitors, clients and employees, and free up valuable space. The wall mount is ideal for a lobby, boardroom or other venue. The TV wall mount also includes built-in cable management to keep cables neatly out of sight.

Full-Motion Adjustment

The TV wall mount features dual arms that extend out to 20.4" (517 mm) from the wall to provide a wide range of movement and accommodate different screen positions and angles. The arms can also fold to tuck in closely to the wall, providing a low profile that enables your display to be positioned just 2.24" (57 mm) from the wall.

You can swivel your display +90 / -90 degrees and tilt +5 / -8 degrees, letting you angle your TV display toward your audience. Plus, the tilt feature lets you adjust the TV so that you can view it comfortably at any height. A built-in level adjustment also offers 5 degree clockwise and counterclockwise turning, to ensure your display is perfectly level.

Secure Installation

The heavy-duty steel construction, dual-arm design and dual-stud mounting for studs placed 16" apart, provides increased durability and security. It safely and securely supports your flat-screen TV, to protect your investment.

FPWARTB2 is backed by a StarTech.com 5-year warranty and free lifetime technical support.

Certifications, Reports and Compatibility



Applications

- Wall-mount your flat-screen TV for optimal viewing
- Ideal for lobbies, boardrooms, meeting spaces and classrooms
- Keep your guests informed and entertained

Features

- Save space with this flat-screen TV wall mount for 32" to 70" TVs (fits curved TVs, with compatible VESA mount)
- Full-motion capability with arm extension up to 20.4" (517 mm)
- Maximum viewing flexibility with a dual-arm design and +90 /-90 degree swivel
- Easy tilt adjustment (tilts +5 /-8 degrees)
- Freely tilts +5° / -8° for easy angle adjustment
- Heavy-duty steel mount for TVs up to 99 lb. (45 kg)

Hardware	Warranty	5 Years
	# of Displays Supported	1
	Articulating	Yes
	Cable Management	Yes
	Mounting Options	Wall-Mount
	VESA Hole Pattern(s)	200x200 mm
		400x200 mm
		300x300 mm
		400x400 mm
		600x400 mm
400x300 mm		
300x200 mm		
Wallmountable	Yes	
Performance	Anti-theft	No
	Display Tilt	+5° / -8°
	Fits Curved TV	Yes
	Maximum Arm Extension	20.4 in [517.5 mm]
	Maximum Display Size	70"
	Minimum Display Size	32"
	Swivel / Pivot	+90° / -90°
	Video Wall	No
Weight Capacity (Per Display)	99.5 lb [45 kg]	
Physical Characteristics	Color	Black
	Enclosure Type	Steel and Plastic
	Product Height	16.5 in [41.8 cm]
	Product Length	25.3 in [64.3 cm]
	Product Width	20.4 in [51.7 cm]
	Weight of Product	14.9 lb [6.8 kg]
Packaging Information	Package Height	3.5 in [90 mm]
	Package Length	16.3 in [41.5 cm]

	Package Width	24.5 in [62.2 cm]
	Shipping (Package) Weight	17.1 lb [7.7 kg]
What's in the Box	Included in Package	<ul style="list-style-type: none"> 1 - wall mount 2 - vertical brackets 2 - horizontal brackets 1 - wrench 4 - bracket screws 4 - nuts 2 - mounting screws 4 - M5x14 mm screws 4 - M6x14 mm screws 4 - M6x30 mm screws 4 - M8x30 mm screws 4 - M8x50 mm screws 4 - small washers 4 - large washers 8 - small spacers 8 - large spacers 6 - screws 6 - concrete screws 6 - bracket washers 1 - instruction manual

Product appearance and specifications are subject to change without notice.