


Triple-Display TV Wall Mount - Menu Board Mount - Landscape

Product ID: FPWMNB

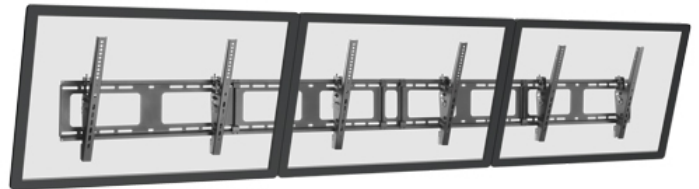

Create a perfectly aligned menu board with this triple-display TV wall mount for 40" to 50" displays. The modular wall-mounting system is easy to set up. Adjust the tilt for all three displays at the same time, and fine-tune the screen level with ease.



Enhance Customer Sales

Digital menu boards are a great way to increase customer sales, promote new offerings, and inform customers at the point of sale. Ideal for restaurants, retail stores and many other businesses, this professional-grade menu board mount supports three 40" to 50" VESA mount TVs in landscape position. It supports a weight capacity of 110 lb. (50 kg) per display, and is compatible with VESA 200x200, 300x200, 300x300, 400x200, 400x300, 400x400, and 600x400.

Adjust Your Display with Ease

For optimum viewing, you can adjust the tilt of all three displays to the same angle simultaneously, without using tools. The multi-screen mount has five fixed tilt settings: 0°/-5°/-10°/-15°/-20°.

Align the Screen Level of All Monitors

To ensure precise alignment of all three TVs, you can fine-tune the level of the displays +3° to -3° using the micro height adjustment feature.

Durable Steel Construction

With its heavy-duty steel construction, the triple-monitor wall bracket provides durable performance.

Fast and Easy Installation

Save time on setup. The hook-and-mount design of the triple-display wall mount makes installation fast and easy.

FPWMNB is backed by a StarTech.com 5-year warranty and free lifetime technical support.

Certifications, Reports and Compatibility



Applications

- Ideal for digital menu boards in restaurants and retail stores
- Create digital signage in customer-facing areas in business lobbies, airports and hospitality centers
- Communicate with visitors in schools, health care centers and other institutional settings

Features

- Create a digital menu board, mounting three 40" to 50" TVs in landscape position
- Tilt all displays to the same angle easily, with five fixed-tilt settings: 0°/-5°/-10°/-15°/-20°
- Align your displays with micro height adjustment, fine-tuning the screen level +3° to -3°
- 3.0" (76 mm) profile to wall, and fast and easy installation
- Steel mount supports VESA 200x200, 300x200, 300x300, 400x200, 400x300, 400x400, 600x400, and up to 110 lb. (50 kg) weight per display

Hardware	Warranty	5 Years
	Cable Management	No
	VESA Hole Pattern(s)	200x200 mm
		300x200 mm
		300x300 mm
		400x200 mm
		400x300 mm
		400x400 mm
600x400 mm		
Wallmountable	Yes	
Performance	Anti-theft	No
	Display Tilt	0 / -5 / -10° / -15° / -20°
	Fits Curved TV	No
	Maximum Display Size	50"
	Minimum Display Size	40"
	Screen Level Adjustment	+3° to -3°
	Video Wall	No
	Weight Capacity (Per Display)	110.5 lb [50 kg]
Physical Characteristics	Color	Black
	Enclosure Type	Steel
	Product Height	8.9 in [22.5 cm]
	Product Length	9.5 ft [2.9 m]
	Product Width	3.1 in [78 mm]
	Weight of Product	36.2 lb [16.4 kg]
	Packaging Information	Package Height
Package Length		29.1 in [74 cm]
Package Width		9.8 in [25 cm]
Shipping (Package) Weight		36.4 lb [16.4 kg]
What's in the Box	Included in Package	4 - Wall Plates
		1 - Small Wall Plate

- 6 - Adapter Brackets
- 8 - Wall Plate Clamps
- 6 - Safety Pins
- 16 - M4 x 6 mm Screws
- 12 - M5 x 14 mm Screws
- 12 - M6 x 14 mm Screws
- 12 - M6 x 30 mm Screws
- 12 - M8 x 30 mm Screws
- 12 - M8 x 50 mm Screws
- 12 - Plate Washers
- 24 - Small Spacers
- 24 - Large Spacers
- 18 - ST6.3 x 55 mm Screws
- 18 - Concrete Anchors
- 18 - D6 Washers
- 1 - 5 mm Hex Key
- 1 - User Manual

Product appearance and specifications are subject to change without notice.