


Cat6 Ethernet Cable - Slim - Snagless RJ45 Connectors - 6 in., Black

Product ID: N6PAT6INBKS

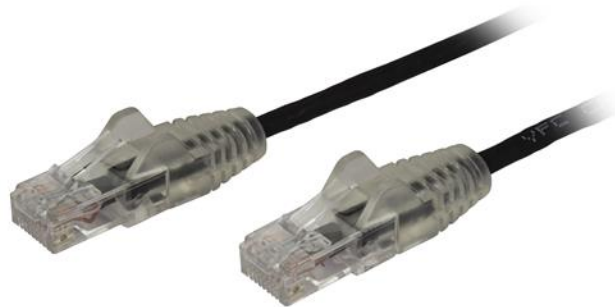

This slim Cat6 Ethernet cable delivers reliable Gigabit network connections in high-density data center applications. It's 36% thinner than standard networking cables, which allows better airflow and heat dissipation in tight spaces..

Easier cable runs

The thinner design also makes this cable more flexible than standard Ethernet cable, so cable runs are easier around corners, in crowded network racks and closets, and through cable-management panels. This durable cable features snagless connectors that protect the RJ45 clips during installation, which makes them less likely to snag or break as you pull them through concealed spaces.

High-quality construction

Each Cat6 cable is manufactured using high-quality copper conductors and is carefully constructed and tested, to keep Near-End Crosstalk (NEXT) well within acceptable limits. This patch cable is constructed with 28 AWG copper wire, to ensure peak performance for your demanding Ethernet applications.

The N6PAT6INBKS is backed by StarTech.com's lifetime warranty for guaranteed reliability.

Certifications, Reports and Compatibility



Applications

- For installation in high-density data centers
- Designed for use with Gigabit networks

Features

- 36% thinner cable for flexible cable installations in crowded network closets and cable-management panels
- Meets the ANSI/TIA-568-C.2 standard for patch cord performance
- Allows better airflow and optimizes heat dissipation
- RJ45 connector-clip protectors eliminate cable snags and breaks during installation
- Black PVC jacket for color coding your connections
- 6 in. in length
- 50-micron gold-plated connectors for a clear signal
- High-quality 28 AWG copper wire

Hardware	Warranty	Lifetime
	Aantal geleiders	4 pair UTP
	Brandbestendigheid	LSZH-rating (weinig rook, geen halogeen)
	Connectormateriaal	Goud
	Kabelstandaard	TIA/EIA-568-B.1-2001 T568B
	Type kabel	Snagless
	Type kabelmantel	PVC - Polyvinyl Chloride
Prestaties	Kabelspecificatie	CAT6 - 250 MHz
Connector(en)	Connector A	1 - RJ-45 Mannelijk
	Connector B	1 - RJ-45 Mannelijk
Fysieke eigenschappen	Breedte product	0.5 in [12 mm]
	Draaddikte	28 AWG
	Gewicht product	0.2 oz [6 g]
	Hoogte product	0.4 in [10 mm]
	Kabellengte	0.5 ft [0.2 m]
	Kleur	Zwart
	Lengte product	0.5 ft [0.2 m]
	Type geleider	Gevlochten koper
Verpakkingsinformatie	Verzendgewicht (verpakt)	0.7 oz [20 g]
Wat wordt er meegeleverd	Meegeleverd	1 - Cat6 patch cable

Product appearance and specifications are subject to change without notice.