


## Computer power cord - C13 to C20, 14 AWG, 3 ft

Product ID: PXTC13C20143

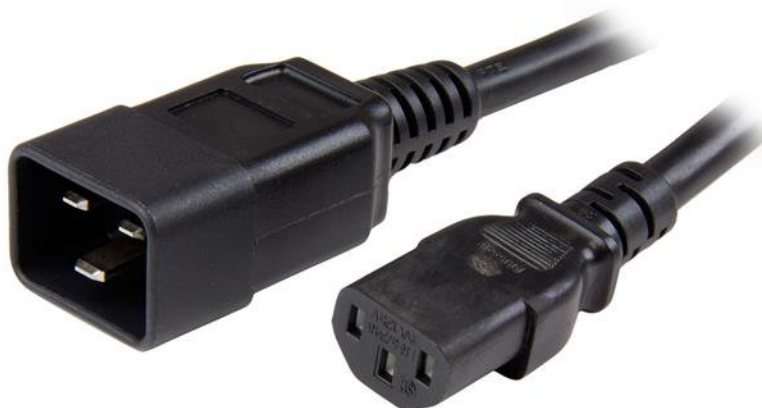

This C13 to C20 power cord from StarTech.com features 14 AWG wire that's suitable for high-power connections, making it perfect for server application and connecting to a Power Distribution Unit (PDU).

Expertly designed and constructed of high-quality materials, the PXTC13C20143 power cord is backed by our lifetime warranty.

### Certifications, Reports and Compatibility



### Applications

- Connect your server to a PDU
- Extend the connection between your server and PDU by up to 3 feet

### Features

- Rated to carry 125V at 15A
- 14 AWG wire
- UL, RoHS compliant

<b>Hardware</b>	Warranty	Lifetime
	Cable Jacket Type	PVC - Polyvinyl Chloride
	Cable Type	SJT
	Number of Conductors	3
<b>Connector(s)</b>	Connector A	1 - IEC 60320 C13 Power
	Connector B	1 - IEC 60320 C20 Power
<b>Special Notes / Requirements</b>	<b>Note</b>	UL Listed
<b>Power</b>	Input Current	15 A
	Input Voltage	125 AC
<b>Physical Characteristics</b>	Cable Length	3 ft [0.9 m]
	Color	Black
	Product Length	3 ft [0.9 m]
	Weight of Product	8 oz [228 g]
	Wire Gauge	14 AWG
<b>Packaging Information</b>	Package Height	1.5 in [38 mm]
	Package Length	11.4 in [29 cm]
	Package Quantity	1
	Package Width	5.7 in [14.5 cm]
	Shipping (Package) Weight	8.3 oz [234 g]
<b>What's in the Box</b>	Included in Package	1 - 3 ft 14 AWG Computer Power Cord - C13 to C20

Product appearance and specifications are subject to change without notice.