


Computer power cord - C13 to C20, 14 AWG, 6 ft

Product ID: PXTC13C20146

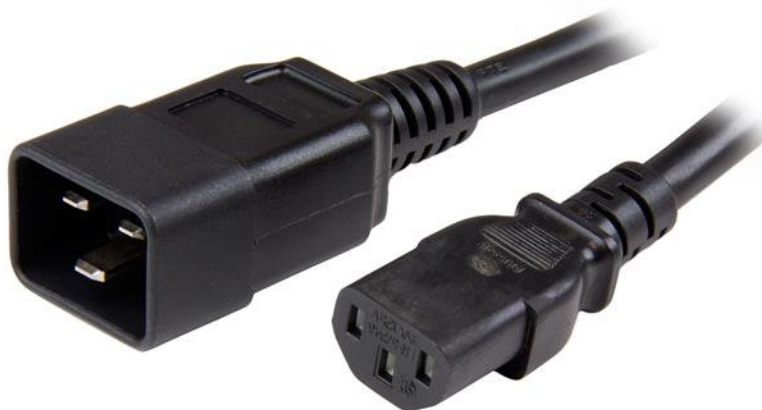

This 6ft C13-to-C20 power cord features 14 AWG wire that's suitable for high-power connections, making it perfect for server applications and connecting to a Power Distribution Unit (PDU).

Expertly designed and constructed of high-quality materials, the StarTech.com PXTC13C20146 power cord is backed by a lifetime warranty.

Certifications, Reports and Compatibility



Applications

- Connect your server to a PDU
- Extend the connection between your server and PDU by up to 6 feet

Features

- Rated to carry 125V at 15A
- 14 AWG wire
- UL, RoHS compliant

Hardware	Warranty	Lifetime
	Cable Jacket Type	PVC - Polyvinyl Chloride
	Cable Type	SJT
	Number of Conductors	3
Connector(s)	Connector A	1 - IEC 60320 C13 Power
	Connector B	1 - IEC 60320 C20 Power
Special Notes / Requirements	Note	UL Listed
Power	Input Current	15 A
	Input Voltage	125 AC
Physical Characteristics	Cable Length	6 ft [1.8 m]
	Color	Black
	Product Length	6 ft [1.8 m]
	Weight of Product	11.8 oz [335 g]
	Wire Gauge	14 AWG
Packaging Information	Package Height	2.7 in [68 mm]
	Package Length	11.4 in [29 cm]
	Package Quantity	1
	Package Width	5.7 in [14.5 cm]
	Shipping (Package) Weight	12.1 oz [342 g]
What's in the Box	Included in Package	1 - 6 ft 14 AWG Computer Power Cord - C13 to C20

Product appearance and specifications are subject to change without notice.