


## Computer power cord - C19 to C20, 14 AWG, 6 ft

Product ID: PXTC19C20146

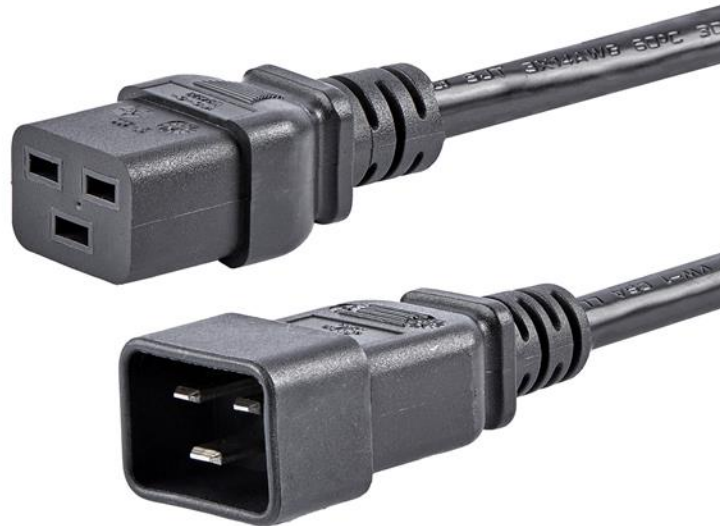

This C19-to-C20 power cord features 14 AWG wire that's suitable for high-power connections, making it perfect for server applications and connecting to a Power Distribution Unit (PDU).

Plus, you can use the cable to extend the reach of your existing power cord by 6 feet, which gives you the extra distance you need to place your devices according to your server room configuration.

Expertly designed and constructed of high-quality materials, the StarTech.com PXTC19C20146 power cord is backed by a lifetime warranty.

### Certifications, Reports and Compatibility



### Applications

- Connect your server to a PDU
- Extend the connection between your server and PDU by up to 6 feet

### Features

- Rated to carry 250V at 15A
- 14 AWG wire
- UL, RoHS compliant

<b>Hardware</b>	Warranty	Lifetime
	Cable Jacket Type	PVC - Polyvinyl Chloride
	Cable Type	SJT
	Number of Conductors	3
<b>Connector(s)</b>	Connector A	1 - IEC 60320 C19 Power
	Connector B	1 - IEC 60320 C20 Power
<b>Special Notes / Requirements</b>	<b>Note</b>	UL Listed
<b>Power</b>	Input Current	15 A
	Input Voltage	250 AC
<b>Physical Characteristics</b>	Cable Length	6 ft [1.8 m]
	Color	Black
	Product Length	6 ft [1.8 m]
	Product Weight	12.6 oz [356 g]
	Wire Gauge	14 AWG
<b>Packaging Information</b>	Package Quantity	1
	Shipping (Package) Weight	12.8 oz [363 g]
<b>What's in the Box</b>	Included in Package	1 - 6 ft 14 AWG Computer Power Cord - C19 to C20

Product appearance and specifications are subject to change without notice.