


12U 19in Hinged Wall Mount Server Rack Cabinet w/ Steel Mesh Door

Product ID: RK1219WALHM

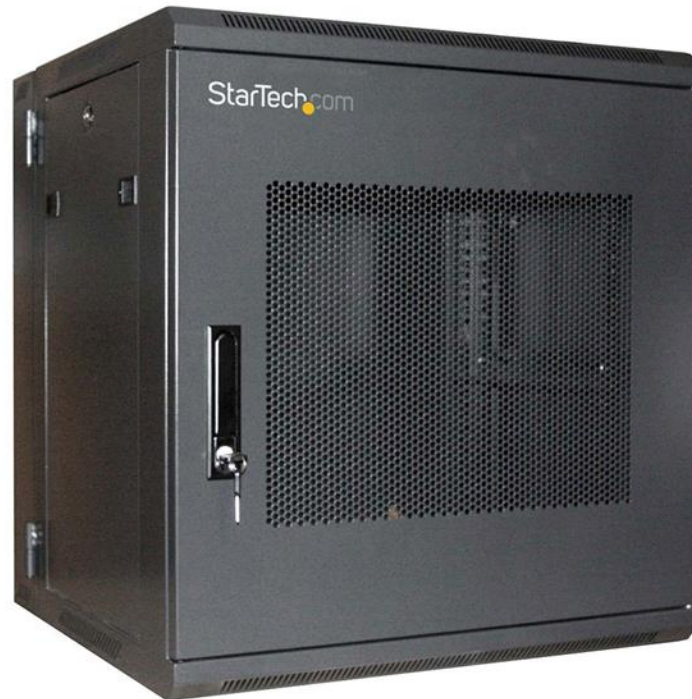

This 12U Server Rack/Cabinet offers a durable solution for mounting valuable server equipment, routers, switches and other networking equipment while saving space and hassle.

The sturdy 12U rack cabinet features a high quality steel design and a vented, steel mesh door to help keep rack mounted equipment safe and cool.

A suitable addition to any server room, wiring closet, manufacturing area, warehouse or locale where networking equipment requires an added level of protection, the 12U rack cabinet accommodates 19in wall mount devices (19" depth) and features a rear-hinged design that makes it easier to access cabling and device ports.

Our 12U Rack Cabinet is designed for guaranteed reliability to ensure a stable rack mount platform for valuable equipment and backed by Lifetime Warranty.

Certifications, Reports and Compatibility



Applications

- Mounting standard 19 in. networking equipment in exposed or unsecure locations

Features

- Unique hinged design swings open for easy access to your equipment
- Cable pass-through at rear of cabinet
- Fan mounts for optional additional cooling
- Removable side panels with lock.
- Sturdy steel design
- Steel mesh door for added security

Hardware	Warranty	Lifetime
	Adjustable Mounting Rails	Yes
	Back Door Construction	Steel
	Back Door Key Lock	Yes
	Cable Management	No
	Casters	No
	Fan(s)	Optional
	Frame Type	Enclosed Cabinet
	Front Door Construction	Steel Mesh
	Front Door Key Lock	Yes
	Front Door Reversible and/or Removable	Removable
	Industry Standards	EIA-310-D
		EIA RS310-C
	Ladder Offset	0 in [0 mm]
	Ladder Type	L-Shape
	Mounting Holes	Square
	Number and Type of Included Cage Nuts	10 - M6
	Rack Type	4-Post
	Side Panel Construction	Solid Steel
	Side Panel(s) Key Lock	Yes
	Side Panels Reversible and/or Removable	Removable
	Style	Wall-Mount
	Tools Included	No
	U Height	12U
	U Markings	No
	Wallmountable	Yes
	Performance	Weight Capacity (Stationary)
Physical Characteristics	Color	Black
	Enclosure Type	Steel

	Internal Depth	20.6 in [522 mm]
	Internal Height	21 in [533.4 mm]
	Internal Width	22 in [560 mm]
	Maximum Mounting Depth	15.4 in [392 mm]
	Minimum Mounting Depth	2.7 in [68 mm]
	Product Height	25 in [635 mm]
	Product Length	21.7 in [550 mm]
	Product Weight	55.5 lb [25.1 kg]
	Product Width	23.5 in [597 mm]
Packaging Information	Flat Pack (Assembly Required)	No
	Shipping (Package) Weight	62.2 lb [28.1 kg]
What's in the Box	Included in Package	1 - Black Hinged Cabinet
		1 - Set of Keys
		1 - Package of Cab Screws and Cage Nuts

Product appearance and specifications are subject to change without notice.