


15U Wall-Mount Server Rack - 12 in. Depth

Product ID: RK15WALLO

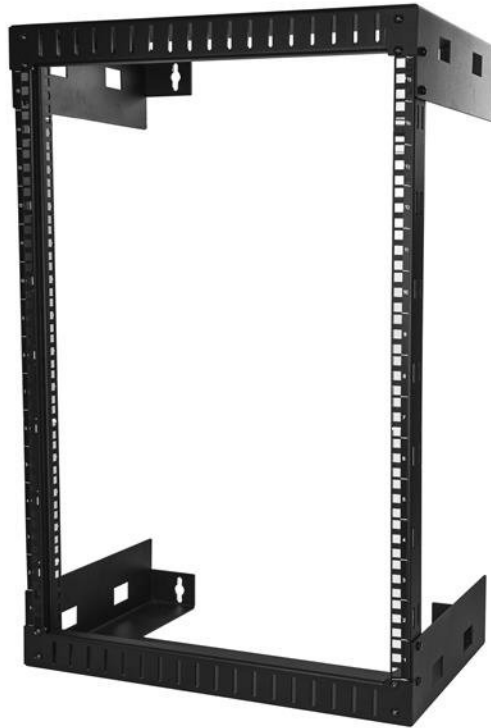

This open-frame wall-mount server rack provides 15U of storage, allowing you to save space and stay organized. The equipment rack can hold up to 198 lb. (90 kg).

Easy, hassle-free installation

The network rack is 12 in. (30.4 cm) deep, so it's perfect for smaller spaces. It's easy to assemble and features mounting holes that are spaced 16 in. apart, making it suitable for mounting on almost any wall, based on common wall-frame stud spacing. The wall-mount rack comes in a flat-pack making it easy to transport and reducing your cost in shipping.

Free up space

You can mount the open-frame rack where space is limited, such as on a server room wall, office, or above a doorway, to expand your workspace and ensure your equipment is easy to access.

Keep your equipment cool and accessible

By having an open frame the server rack provides passive cooling to equipment. Additionally, the open frame provides easy access and configurability to your equipment, allowing you to maximize productivity.

The RK15WALLO is backed by a StarTech.com 5-year warranty and free lifetime technical support.

Certifications, Reports and Compatibility



Applications

- Perfect for installing network switches out of the way and high up on a wall in a branch office, warehouse, or superstore location
- Mount audio/video broadcast or distribution components
- Ideal for small and medium businesses requiring small rack solutions dispersed throughout the organization

Features

- Save space by mounting your equipment on the wall
- Easy installation with mounting holes spaced 16 in. apart to match standard wall studs
- Comes in a flat-pack making it easy to transport
- Open frame provides passive cooling for equipment

Hardware	Warranty	5 Years
	Frame Type	Open Frame
	Industry Standards	EIA/ECA-310-E
	Mounting Hole Types	Square (For Cage Nut)
	Mounting Rail Profile	G-Shape
	Rack Type	2-Post
	Special Features	Easy Assembly
		U-Markings
	Wall-Mountable	
	U Height	15U
	Wallmountable	Yes
Performance	Weight Capacity	198.9 lb [90 kg]
Physical Characteristics	Color	Black
	Construction Material	Steel
Product Measurements	Maximum Mounting Depth	12 in [30.5 cm]
	Product Height	30.5 in [77.5 cm]
	Product Length	12.2 in [31 cm]
	Product Width	19.9 in [50.5 cm]
	Weight of Product	21.4 lb [9.7 kg]
Packaging Information	Flat Pack (Assembly Required)	Yes
	Package Height	4.9 in [12.5 cm]
	Package Length	31.5 in [80 cm]
	Package Width	20.9 in [53 cm]
	Shipping (Package) Weight	25.7 lb [11.7 kg]
What's in the Box	Included in Package	60 - M6 Screws
		60 - M6 Cage Nuts
		60 - Washers
		16 - Assembly Screws
		2 - Vertical Rails
		2 - Horizontal Brackets

Product appearance and specifications are subject to change without notice.