

2 m (6.6 ft.) Angled Lightning to USB Cable - Apple MFi Certified - Black

Product ID: RUSBLTMM2MBR



This angled Lightning to USB cable withstands the demands of charging and syncing your mobile devices. The angled Lightning connector gives you easy access to your mobile device, even while charging. And, the longer cable is ideal for overcoming distance restrictions.


Built for Daily Use

With Kevlar® aramid fiber reinforcement, the durable Lightning cable is sheltered from the stress of frequent bends and twists, which allows the cable to flex without over-stretching.



Cable Key Features

- 1. Aramid fiber adds strength and durability to the cable
- 2. Insulated conductors reduce friction, provide more flexibility
- 3. EMI (electromagnetic interference) protection with aluminum-mylar foil and braided shielding
- 4. TPE (thermoplastic elastomer) cable jacket is softer and more flexible than a standard PVC cable

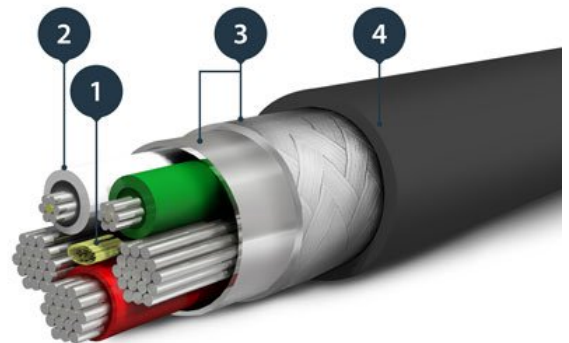

Flexible Strain Relief

Constructed to prevent the connector from separating from the cable jacket, the extra-long strain relief molding is tested to withstand over 10,000+ bend cycles at a 180° angle.



Connector Key Features

- 1. Lightning connector provides 12W for charging your iOS devices
- 2. Metal shield protects circuit board from EMI and reinforces the connection point
- 3. Strain relief tested to tolerate over 10,000+ bend cycles at a 180-degree angle

RUSBLTMM2MBR is an Apple MFi certified Lightning cable backed by a StarTech.com 2-year warranty.

Note: DuPont™ and Kevlar® are trademarks or registered trademarks of E.I. du Pont de Nemours and Company.



Certifications, Reports and Compatibility



Made for



iPhone | iPad

Applications

- Charge and sync your Lightning mobile devices
- Text, work, or game without the cable getting in the way
- Easy access in both portrait and landscape mode

Features

- Charge your devices with a cable designed to stay out of your way and built to withstand your daily routine.
- Protected against the stress of frequent twists, this Lightning cable is reinforced with aramid fiber.
- Extended strain relief tested to tolerate over 10,000+ bend cycles at 180-degree angle.
- Provide flexible connections with this MFi Certified Lightning cable with a soft TPE jacket.
- Shielded against EMI, this heavy-duty Lightning cable has a metal guard protecting the circuit board.

| | | |
|---------------------------------|---------------------------|--|
| Hardware | Warranty | 2 Years |
| | Cable Jacket Type | TPE - Thermoplastic Elastomers |
| | Cable Shield Type | Aluminum-Mylar Foil with Braid |
| | Connector Plating | Nickel |
| Performance | Type and Rate | USB 2.0 - 480 Mbit/s |
| Connector(s) | Connector A | 1 - USB Type-A (4 pin) USB 2.0 Male |
| | Connector B | 1 - Apple Lightning Connector (8-pin) Male |
| Physical Characteristics | Cable Length | 6.6 ft [2 m] |
| | Color | Black |
| | Connector Style | Angled |
| | Product Height | 0.3 in [0.7 cm] |
| | Product Length | 6.6 ft [2 m] |
| | Product Width | 1 in [26.1 mm] |
| | Weight of Product | 2.3 oz [65 g] |
| | Wire Gauge | 22/32 AWG |
| Packaging Information | Package Height | 1.2 in [30 mm] |
| | Package Length | 6.3 in [16 cm] |
| | Package Width | 3 in [75 mm] |
| | Shipping (Package) Weight | 0.1 lb [0 kg] |
| What's in the Box | Included in Package | 1 - 2 m Lightning Cable |

Product appearance and specifications are subject to change without notice.