

Long Range USB VGA KVM Console Extender over Cat5 UTP - 1000 ft

Product ID: SV565UTPUL




The SV565UTPUL Long Range USB VGA KVM Console Extender over Cat5 UTP (1000 ft) lets you control a server, computer or multiple computers (connected through KVM Switch) over a standard Cat5 or Cat6 UTP network cable connection, at distances of up to 1000ft (300m) away.

You can use your existing USB keyboard, USB mouse, and monitor to access both the server room and your office computer, saving space and avoiding the need for a dedicated remote console by allowing you to switch between workstation view and KVM view at the remote location.

This product is TAA compliant and backed by a Startech.com 3-year warranty with free lifetime technical support.

The SV565UTPUL gives you long range control of any VGA + USB computing device:

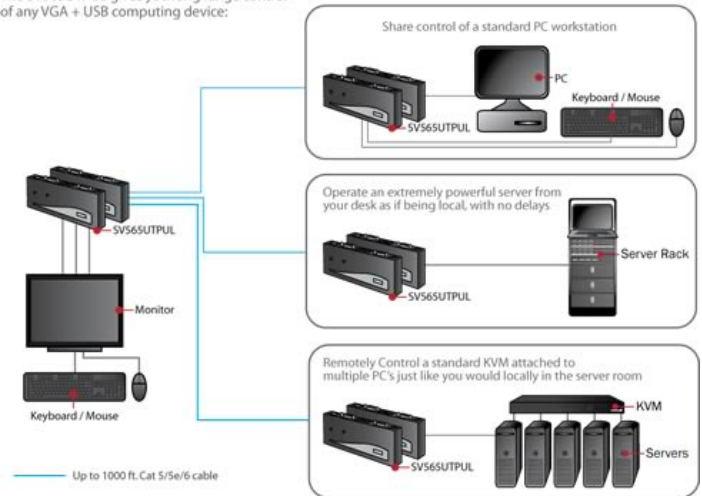

Certifications, Reports and Compatibility



Applications

- Control remote machines and security monitoring systems
- Monitor computer-controlled equipment in a factory or warehouse at a distance
- Use one or more servers in a server room from a remote location
- Allow two users to share one PC or KVM

Features

- High resolution support: Up to 1920x1200(WUXGA)/1600x1200(UXGA)
- Kit includes both local and remote units
- Compatibility mode enables hotkey commands to be passed to connected StarView KVMs
- Max Resolution Limit feature caps the resolution to prevent the resolution setting from exceeding the capability of the connected display
- USB computers are supported at the host and remote locations (USB keyboard and mouse required for remote console)
- Supports auto-switching between host and remote users or dedicated control
- Compatible with CAT 5, 5e, or 6 UTP cabling
- Intuitive hotkey commands
- Hotkey controlled Equalizer(sharpness), Gain(brightness), and RGB Skew adjustments
- Supports most combo keyboard and mouse sets (including Wireless)
- PS/2 and USB host PC's supported via the appropriate PS2 or USB KVM cable (USB style included)

| | | |
|-------------------------------------|------------------------------|--|
| Hardware | Warranty | 3 Years |
| | Audio | No |
| | Cables Included | Yes |
| | KVM Ports | 2 |
| | Number of Monitors Supported | 1 |
| | PC Interface | USB |
| | PC Video Type | VGA |
| | Rack-Mountable | No |
| Performance | IP Control | No |
| | Max Transfer Distance | 300 m (984 ft) |
| | Maximum Analog Resolutions | UXGA - 1600x1200, WUXGA - 1920x1200 |
| | Port Selection Support | Push Button and Hotkeys |
| | Wide Screen Supported | Yes |
| Connector(s) | Console Interface(s) | 2 - VGA (15 pin, High Density D-Sub) Female 4 - USB Type-A (4 pin) USB 2.0 Female |
| | Host Connectors | 2 - VGA (15 pin, High Density D-Sub) Female |
| | Other Interface(s) | 2 - RJ-45 Female |
| Software | OS Compatibility | OS independent; No software or drivers required |
| Special Notes / Requirements | Note | Supports most combo keyboard and mouse sets (including Wireless) |
| Indicators | LED Indicators | 2 - Local indicator 2 - Remote indicator |
| | Power | Center Tip Polarity |
| | Input Current | 0.8A |
| | Input Voltage | 110V-240V AC |
| | Output Current | 1.5A |
| | Output Voltage | 12 DC |
| | Plug Type | M |
| | Power Consumption (In Watts) | 18 |
| | Power Source | AC Adapter Included |
| Environmental | Humidity | 0~80% RH |
| | Operating Temperature | 0°C to 40°C (32°F to 104°F) |

| | | |
|---------------------------------|---------------------------|---|
| | Storage Temperature | -20°C to 60°C (-4°F to 140°F) |
| Physical Characteristics | Color | Black |
| | Enclosure Type | Steel |
| | Product Depth | 2.8 in [70 mm] |
| | Product Height | 0.8 in [20 mm] |
| | Product Weight | 22 oz [622 g] |
| | Product Width | 6.2 in [157 mm] |
| Packaging Information | Shipping (Package) Weight | 3 lb [1.4 kg] |
| What's in the Box | Included in Package | <p>2 - KVM Extenders (1x Local, 1x Remote)</p> <p>2 - 2n1 USB VGA KVM Cables</p> <p>1 - Rubber Feet</p> <p>1 - Universal power adapter: comes ready for NA/EU/UK only when you buy in NA/EU/UK; comes ready for Australia and New Zealand only when you buy in Australia and New Zealand</p> <p>1 - User Manual</p> |

Product appearance and specifications are subject to change without notice.