


1 ft SuperSpeed USB 3.0 Cable A to B - M/M

Product ID: USB3SAB1

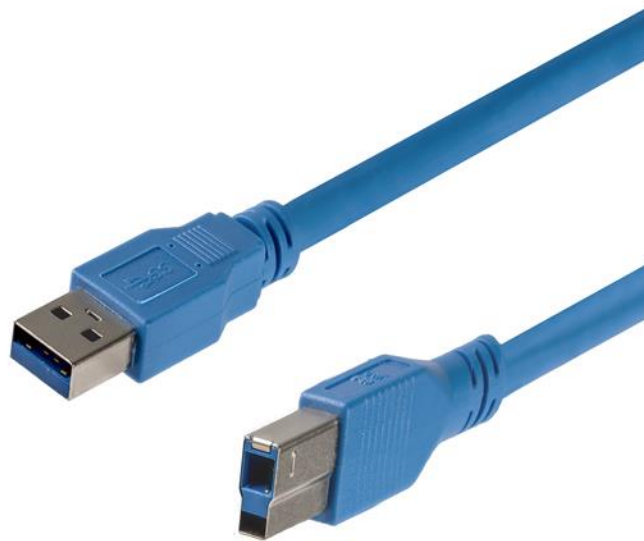

StarTech.com's 1-foot USB 3.0 cable (A-B, male-male) offers a durable, high quality connection that harnesses the full capability of the USB 3.0 standard.

Designed for next-generation SuperSpeed USB device connections, the 1-foot USB 3.0 cable supports a throughput of up to 5Gbps when used with a USB 3.0 host and device - an astounding 10x the capability of USB 2.0 (480Mbps).

Our 1-foot USB 3.0 cable features high quality Shielded Twisted Pair (STP) construction, helping to prevent electro-magnetic interference and ensuring reliable data communication.

The 1ft USB 3.0 cable is backed by our Lifetime Warranty, providing guaranteed quality and reliability.

Certifications, Reports and Compatibility



Applications

- Connect a SuperSpeed USB 3.0 device (Hubs, external storage device) to an USB 3.0 capable PC, laptop, or Server

Features

- Shielded Twisted Pair (STP) design which prevents electro-magnetic interference (EMI)
- Support for data transfer rates up to 5Gbps - 10x faster than USB 2.0
- Backward compatible with USB 2.0
- Nickel-plated connectors

| | | |
|---------------------------------|---------------------------|--|
| Hardware | Warranty | Lifetime |
| | Cable Jacket Type | PVC - Polyvinyl Chloride |
| | Cable Shield Type | Aluminum-Mylar Foil with Braid |
| Performance | Type and Rate | USB 3.0 - 5 Gbit/s |
| Connector(s) | Connector A | 1 - USB Type-A (9 pin) USB 3.0 Male |
| | Connector B | 1 - USB Type-B (9 pin) USB 3.0 Male |
| Physical Characteristics | Cable Length | 1 ft [0.3 m] |
| | Color | Blue |
| | Product Length | 1 ft [0.3 m] |
| | Product Weight | 0.9 oz [26 g] |
| | Wire Gauge | 28 AWG |
| Packaging Information | Shipping (Package) Weight | 1.2 oz [35 g] |
| What's in the Box | Included in Package | 1 - 1 ft SuperSpeed USB 3.0 Cable A to B - M/M |

Product appearance and specifications are subject to change without notice.